


SIVACON, Roof, EMC, EMC, IP40, W: 1000 mm, T: 500 mm, zinc-plated

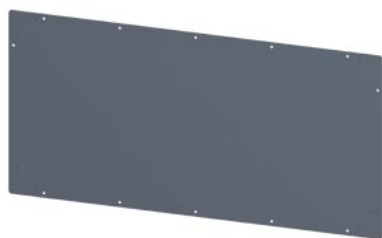

Model		
product brand name	SIVACON	
product designation	top plate	
design of the product	EMC	
design of the surface	zinc plated	
design of the product EMC version	Yes	
Protection class		
protection class IP	IP40	
Suitability		
suitability for use for outside use	No	
Product details		
product component		
● cable entry		
● ventilation		
Mechanical Design		
width	1 000 mm	
depth	500 mm	
material	steel	
Approvals Certificates		
General Product Approval		Test Certificates
		other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
Miscellaneous	 Environmental Confirmations

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875
Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs
Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1005-2UD12-0A
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1005-2UD12-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1005-2UD12-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

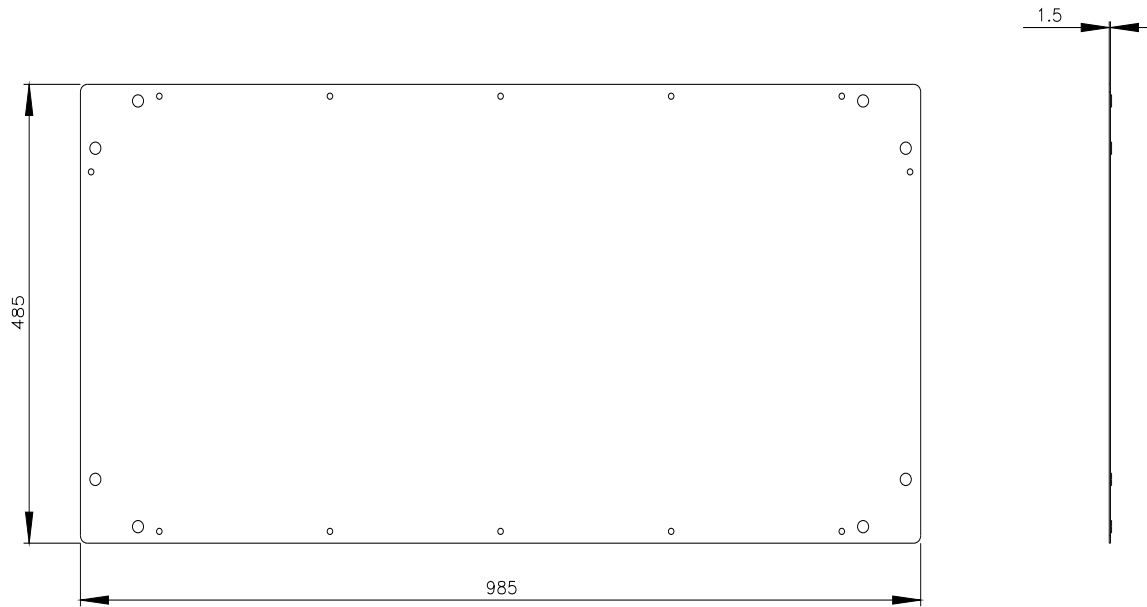

last modified:

7/24/2023 

