

# CES-STPG-GY-15 - Cable sleeve



1410521

<https://www.phoenixcontact.com/in/products/1410521>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable sleeve, small, no. of conductors: 1, type: Round cable, slotted, external cable diameter: 1x 13.9 mm ... 14.2 mm, material: SEBS (halogen-free), color: gray, length: 29.5 mm, width: 19.5 mm, height: 17 mm

## Product description

Slotted cable sleeve

## Commercial data

|                                      |                     |
|--------------------------------------|---------------------|
| Item number                          | 1410521             |
| Packing unit                         | 10 pc               |
| Minimum order quantity               | 10 pc               |
| Sales key                            | BF7                 |
| Product key                          | AF7CCX              |
| Catalog page                         | Page 680 (C-2-2019) |
| GTIN                                 | 4046356797030       |
| Weight per piece (including packing) | 5.36 g              |
| Weight per piece (excluding packing) | 5.12 g              |
| Customs tariff number                | 40169997            |
| Country of origin                    | PL                  |

# CES-STPG-GY-15 - Cable sleeve

1410521

<https://www.phoenixcontact.com/in/products/1410521>




## Technical data

### Product properties

|                   |              |
|-------------------|--------------|
| Product type      | Cable sleeve |
| No. of conductors | 1            |

### Dimensions
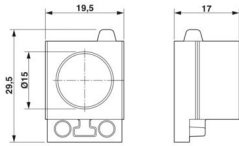
|                     |                                                                                    |
|---------------------|------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width               | 19.5 mm                                                                            |
| Height              | 17 mm                                                                              |
| Length              | 29.5 mm                                                                            |

### Material specifications

|                                        |                     |
|----------------------------------------|---------------------|
| Material                               | SEBS (halogen-free) |
| Flammability rating according to UL 94 | V0                  |

### Cable/line

|                         |                        |
|-------------------------|------------------------|
| External cable diameter | 1x 13.9 mm ... 14.2 mm |
|-------------------------|------------------------|

### Characteristics

|                    |             |
|--------------------|-------------|
| Seal size          | small       |
| Design, Format     | Round cable |
| Design, Cable seal | slotted     |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                           |
|---------------------------------|---------------------------|
| Degree of protection            | IP54                      |
| Ambient temperature (operation) | -40 °C ... 80 °C (static) |

# CES-STPG-GY-15 - Cable sleeve


1410521

<https://www.phoenixcontact.com/in/products/1410521>



## Drawings

Dimensional drawing

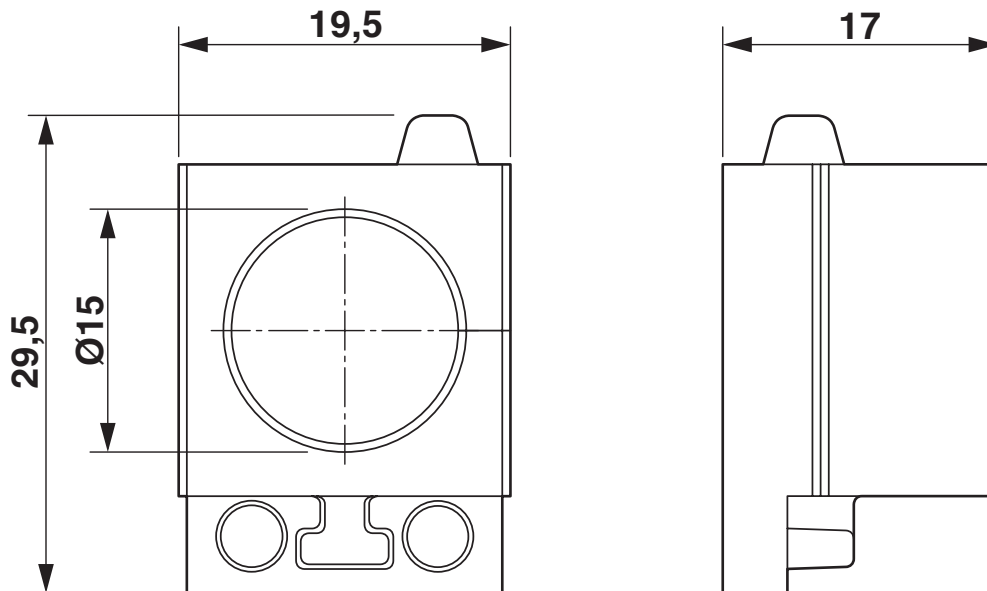

Dimensional drawing

# CES-STPG-GY-15 - Cable sleeve



1410521

<https://www.phoenixcontact.com/in/products/1410521>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1410521>

### DNV

Approval ID: TAE00003VJ

# CES-STPG-GY-15 - Cable sleeve



1410521

<https://www.phoenixcontact.com/in/products/1410521>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27144425 |
| ECLASS-12.0 | 27144425 |
| ECLASS-13.0 | 27144425 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000451 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

# CES-STPG-GY-15 - Cable sleeve



1410521

<https://www.phoenixcontact.com/in/products/1410521>

## Environmental product compliance

|                                         |                                          |
|-----------------------------------------|------------------------------------------|
| EU RoHS                                 |                                          |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |                                          |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|                                         | No hazardous substances above the limits |
| EU REACH SVHC                           |                                          |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |
| EF3.0 Climate Change                    |                                          |
| CO2e kg                                 | 0.073 kg CO2e                            |

# CES-STPG-GY-15 - Cable sleeve

1410521

<https://www.phoenixcontact.com/in/products/1410521>



## Accessories

### KDT-ST 15 - Filler plug

3062045

<https://www.phoenixcontact.com/in/products/3062045>

Filler plug, material: PA, length: 20 mm, diameter: 15 mm



---

### CES-B10-HFFS-PLBK - Sealing frame

0801663

<https://www.phoenixcontact.com/in/products/0801663>

Sealing frame, With locking latch, design: B10, Number of cable seals (small): 6, material: PA (halogen-free), color: black, length: 99.2 mm, width: 58 mm, height: 20 mm



# CES-STPG-GY-15 - Cable sleeve

1410521

<https://www.phoenixcontact.com/in/products/1410521>



## CES-B16-HFFS-PLBK - Sealing frame

0801662

<https://www.phoenixcontact.com/in/products/0801662>



Sealing frame, With locking latch, design: B16, Number of cable seals (small): 8, material: PA (halogen-free), color: black, length: 120 mm, width: 58 mm, height: 20 mm

---

## CES-B24-HFFS-PLBK - Sealing frame

0801661

<https://www.phoenixcontact.com/in/products/0801661>



Sealing frame, With locking latch, design: B24, Number of cable seals (small): 10, material: PA (halogen-free), color: black, length: 147 mm, width: 58 mm, height: 20 mm

# CES-STPG-GY-15 - Cable sleeve

1410521

<https://www.phoenixcontact.com/in/products/1410521>



## CES-B10-SFFS-PLBK - Sealing frame

0801660

<https://www.phoenixcontact.com/in/products/0801660>



Sealing frame, with screw locking, design: B10, Number of cable seals (small): 6, material: PA (halogen-free), color: black, length: 99.2 mm, width: 58 mm, height: 20 mm

---

## CES-B16-SFFS-PLBK - Sealing frame

0801659

<https://www.phoenixcontact.com/in/products/0801659>



Sealing frame, with screw locking, design: B16, Number of cable seals (small): 8, material: PA (halogen-free), color: black, length: 120 mm, width: 58 mm, height: 20 mm

# CES-STPG-GY-15 - Cable sleeve

1410521

<https://www.phoenixcontact.com/in/products/1410521>



## CES-B24-SFFS-PLBK - Sealing frame

0801658

<https://www.phoenixcontact.com/in/products/0801658>



Sealing frame, with screw locking, design: B24, Number of cable seals (small): 10, material: PA (halogen-free), color: black, length: 147 mm, width: 58 mm, height: 20 mm

---

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

[info@phoenixcontact.co.in](mailto:info@phoenixcontact.co.in)