


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0150200444](#)  
**Status:** **Active**  
**Overview:** Premo-Flex Flat-Flexible Cable (FFC) Jumpers  
**Description:** 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 254.00mm Cable Length, Gold (Au) Plating, 40 Circuits

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">Product Specification PS-15020-001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Packaging Specification PK-15020-001-001 (PDF)</a>	

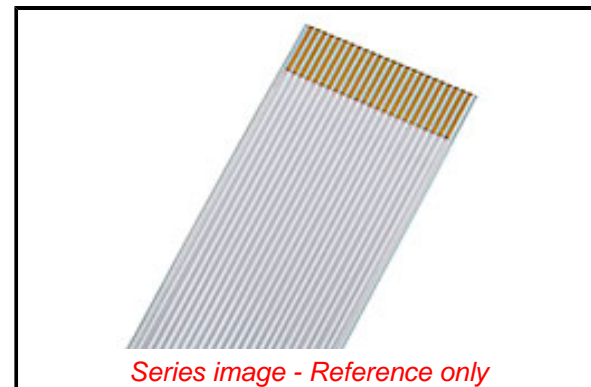

**General**

Product Family	Cable
Series	<a href="#">15020</a>
Comments	Contacts on opposite sides, Type D
Crimp Quality Equipment	Yes
Overview	<a href="#">Premo-Flex Flat-Flexible Cable (FFC) Jumpers</a>
Product Name	Premo-Flex FFC Jumper
UPC	884982179066

**Physical**

Cable Length	254.00mm
Circuits (Loaded)	40
Material - Plating Mating	Gold
Net Weight	3.252/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable

**Electrical**

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-15020-001-001
Product Specification	PS-15020-001-001
Sales Drawing	SD-15020-001

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2020)4578-DC (25  
June 2020)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[15020 Series](#)

**Mates With**

Easy-On FFC/FPC Connector: <br>  
[5051104091](#) , [541044031](#) , [541324062](#) ,  
[5019514010](#) , [5019514030](#) , [5019514050](#) ,  
[525594052](#) , [5034 804000](#)