



Profile Tube D30, natural

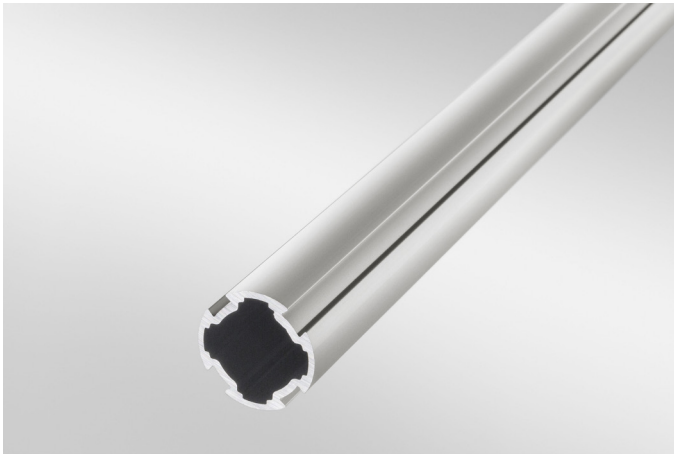

It is the special geometry of Profile Tube D30 that makes this product so versatile. It features four smooth, undercut flanks, each of which is enveloped by a Fastener D30, resulting in a mechanically locked connection with a strong and lasting hold. Struts can be separately fastened to all four of the flanks. Profile Tubes D30 are made of durable and lightweight aluminium and can be easily cut to the desired length.

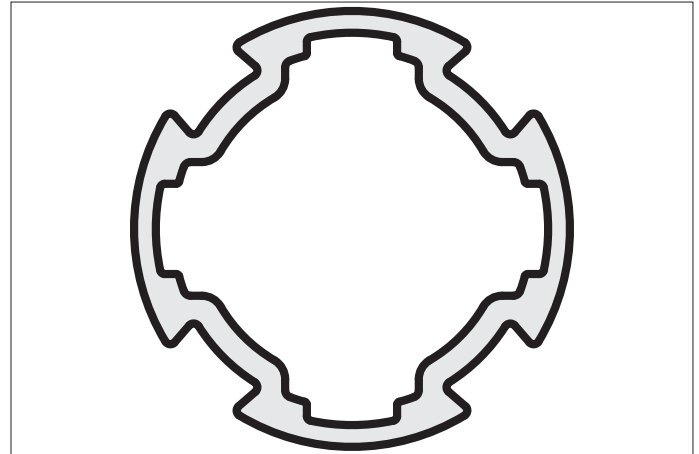

Scope of Delivery

Technical note

[0.0.628.28](#) For more information, please click here!

Properties	
Article number	0.0.628.28
Colour	natural
Delivery unit	cut-off max. 6000 mm
Weight	0.53 kg/m
Material	Al, anodized
Cross-sectional area	1.97 cm ²
Moment of Inertia, torsional	2.44 cm ⁴
Moment of Inertia, x-axis	1.71 cm ⁴
Moment of Inertia, y-axis	1.71 cm ⁴
Resistance Moment, x-axis	1.14 cm ³
Resistance Moment, y-axis	1.14 cm ³

Accessoires	
0.0.637.04	Cap, Tube D30 ESD, black similar to RAL 9005
0.0.629.78	Cap, Tube D30, grey similar to RAL 7042
0.0.643.96	Tube End Cap D30, grey similar to RAL 7042
0.0.644.65	Tube End Cap D30 ESD, black similar to RAL 9005
0.0.671.30	Slide Strip D30 with Side Guide H13, grey similar to RAL 7042
0.0.664.72	Cable Guide Profile D30, grey similar to RAL 7042
0.0.671.98	Universal Holder D30, grey similar to RAL 7042
0.0.671.33	Slide Strip D30 with Side Guide H13 ESD, black similar to RAL 9005