

Jacketed Zip planar cable — 151 series

order information

Part No. & Description	Part No. & Description	No. of Conductors	Dimension "A"	Dimension "B"	Dimension "C"
Extruded PVC Jacket	Aluminum/Poly Shield with Extruded PVC Jacket (2 drain wires)				
843-151-2811-009	843-151-2831-009	9	.450(11,43)	.400±.007(10,16±0,18)	.510
843-151-2811-010	843-151-2831-010	10	.500(12,70)	.450±.007(11,43±0,18)	.560
843-151-2811-014	843-151-2831-014	14	.700(17,78)	.650±.007(16,51±0,18)	.760
843-151-2811-015	843-151-2831-015	15	.750(19,09)	.700±.011(17,78±0,28)	.810
843-151-2811-016	843-151-2831-016	16	.800(20,32)	.750±.011(20,32±0,28)	.860
843-151-2811-020	843-151-2831-020	20	1.000(25,40)	.950 ± .011(24,13 ±0,28)	1.060
843-151-2811-024	843-151-2831-024	24	1.200(30,48)	1.150±.011(29,21±0,28)	1.260
843-151-2811-025	843-151-2831-025	25	1.250(31,79)	1.200±.011(30,48±0,28)	1.310
843-151-2811-026	843-151-2831-026	26	1.300(33,02)	1.250±.011(31,75±0,28)	1.360
843-151-2811-034	843-151-2831-034	34	1.700(43,18)	1.650±.011(41,90±0,28)	1.760
843-151-2811-036	843-151-2831-036	36	1.800(45,72)	1.750±.015(44,45±0,38)	1.860
843-151-2811-037	843-151-2831-037	37	1.850(46,99)	1.800±.015(45,72±0,38)	1.910
843-151-2811-040	843-151-2831-040	40	2.000(50,80)	1.950±.015(49,53±0,38)	2.060
843-151-2811-050	843-151-2831-050	50	2.500(63,50)	2.450±.015(62,23±0,38)	2.560
843-151-2811-060	843-151-2831-060	60	2.000(76,20)	2.950±.015(74,93±0,38)	3.060
843-151-2811-064	843-151-2831-064	64	3.200(81,28)	3.150±.015(80,01±0,38)	3.260


typical crosstalk characteristics

(10-foot sample, 2-lines driven)

Part Number	Rise Time (ns)	NE %	FE %
843-151-2811 Series	3.0	4.4	1.2
	5.0	4.3	.8
	7.0	4.3	.6
843-151-2831 Series	3.0	.3	.7
	5.0	.2	.5
	7.0	.2	.4

Dimensions and characteristics subject to change without notice.

843-151-2811 SERIES UNSHIELDED

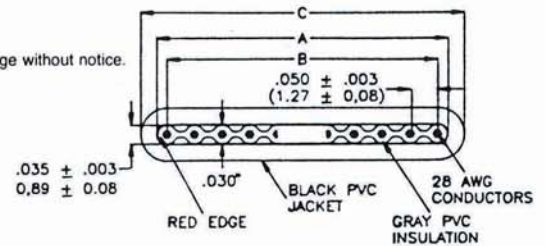

843-151-2831 SERIES SHIELDED

