

HD 4/10 X CLASSIC

Compact HD 4/10 X Classic high-pressure cleaner with automatic pressure relief and integrated hose reel. Very ergonomic and mobile thanks to retractable pull handle and robust wheels.



Order no.


1.520-978.0

Technical data

EAN code		4054278826035
Current type	Ph / V / Hz	1 / 220 / 50
Flow Rate	l/h	400
Operating pressure	bar	100 – max. 145
Weight without accessories	kg	17.5
Weight incl. packaging	kg	21
Dimensions (L × W × H)	mm	335 × 320 × 845

Equipment

Power nozzle	■
Three piston axial pump	with stainless steel pistons
■ included in delivery.	

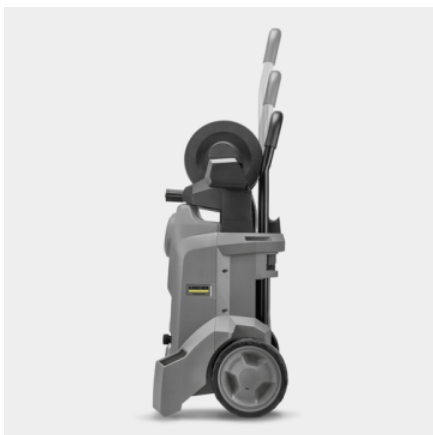

Outstanding mobility

- The robust D180 wheels are ideal for tough applications.
- Extendible handle for convenient transport over short distances.
- Additional handle makes it easier to carry the machine, e.g. up steps.



Perfect ergonomics

- Just one on/off switch for foolproof operation.
- The hose reel offers high comfort and reduced set-up time.
- Ergonomic and effortless trigger gun that is convenient to use.



Compact design

- Very easy to transport thanks to its low weight.
- Space saving and easy to store.

EQUIPMENT FOR HD 4/10 X CLASSIC

1.520-978.0



		Order no.	Description	
TRIGGER GUNS				
Pistol	1	9.751-376.0		■
SPRAY LANCES				
Spray lance				
600 mm spray lance	2	9.751-140.0	600 mm long, zinc coated spray lance with hand screw connection. Not rotatable.	■
Spray lance 850 mm	3	9.751-146.0	Galvanised spray lance with manual screw fitting for high-pressure cleaners in the Classic range from Kärcher. Not rotatable. Length: 850 mm.	□
NOZZLE UNION / SPACER				
Nozzle union				
Nozzle connector	4	5.401-210.0	For protecting and connecting Kärcher power nozzles to spray lances (M 18 × 1.5 IG).	■
ROTARY NOZZLES (DIRT BLASTERS)				
Dirt Blaster, small				
Dirt blaster for replacement 028, small, 028	5	4.747-030.0		□
MULTIPLE-JET NOZZLES				
Triple nozzles				
Triple nozzle, 028	6	4.767-144.0	Triple nozzle with manual nozzle changeover. Convenient spray adjustment. For machines with an injector, the low-pressure flat stream is useful for cleaning agent suction and application. Connection M 18 × 1.5.	□
ECO!BOOSTER				
eco!Booster TR 030	7	2.113-084.0	eco!Booster for cold and hot water high-pressure cleaners (nozzle size 030) with 50% more area performance than the Kärcher power nozzle; ideal for delicate surfaces.	□
DICHTUNGEN FÜR TR-GEWINDE				
Spare part set seals TR	8	2.880-001.0		□
FLOOR AND HARD SURFACE CLEANER				
Machine-specific nozzle kits for FR Classic				
Nozzle kit for FR Classic, 034	9	2.885-313.0	Nozzle kit specifically for FR Classic surface cleaner.	□
FOAM SYSTEMS				
Cup foam lance				
Cup foam lance, 1200 l/h -	10	6.394-668.0	Short, handy foam lance with adjustable spray angle with 1 litre detergent tank. Ideal for cleaning cars due to its compact design.	□

■ Included in delivery. □ Available accessories.