


Standard Thermocouple Connector Plug IS-J-M Type J IEC

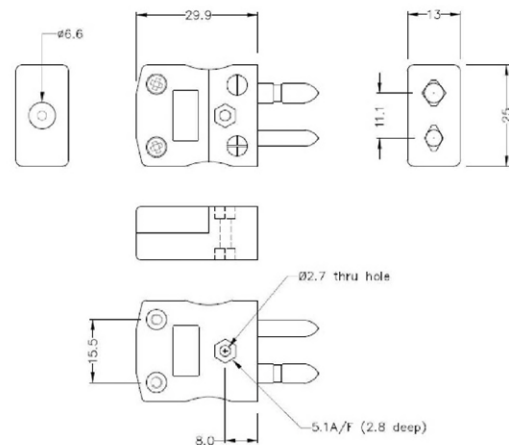

Standard in-line Plug
(dimensions in mm)

General Description	Contacts are polarised to prevent incorrect connection
Thermocouple Type	J IEC
Connector Type	Plug
Connector Size	Standard
Colour	Black
Max. Temperature	220°C
Pins	Solid Round Pins
+Positive Contact	Iron
-Negative Contact	Copper Nickel
Standards Met	EN 50212:1997. RoHS