

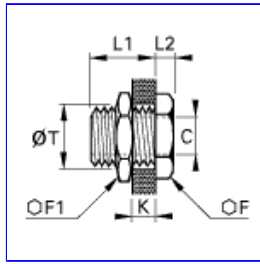


1817
BULKHEAD ADAPTOR, BSP
PARALLEL

1817

Specifications

maximum working pressure	bar 150	MPa 15,0	psi 2176
working temperature	°C (Celsius) From -20 to 180	F (Fahrenheit) From -4 to 356	K (Kelvin) From 253 to 453
body	stainless steel 316L		


 


1817 BULKHEAD ADAPTOR, BSP PARALLEL

1817

Dimensions

convert weight : kg | oz
convert dimensions : mm | inch

		C	F (mm)	F1 (mm)	K (mm)	Kmaxi (mm)	L1 (mm)	L2 (mm)	ØT (mm)	ØTmini (mm)	 (kg)
1817 00 10		G1/8	19,0	22,0	9,0		14,0	4,0	16,5		0,030
1817 00 13		G1/4	24,0	27,0	15,0		21,0	4,0	20,5		0,053
1817 00 17		G3/8	30,0	32,0	14,0		21,0	5,0	26,5		0,089
1817 00 21		G1/2	32,0	36,0	20,0		27,0	6,0	28,5		0,109
1817 00 27		G3/4	41,0	41,0		22,5	30,0	6,0		34,5	0,000
1817 00 34		G1	46,0	50,0		24,5	34,0	8,0		42,5	0,000