



Double open-ended spanner sets MOTOR, inch

10a/7

Product no. **96404306**
GTIN **4018754080762**
Model **MOTOR 10a/7**



Label.

Double open-ended spanner set MOTOR 10a/7 1/4x5/16-1.1/8x1.5/16 7 pcs.

Properties.

- **imperial, differing** end sizes
- straight design, jaws angled 15°
- durable, slim and lightweight design
- high flexural strength due to double-T profile
- STAHLWILLE's rounded finish ensures a non-slip, pleasant feel
- drop-forged, hardened, and cooled in an oil bath
- Chrome Alloy Steel, chrome-plated
- in robust polyester roll-up tool pouch with Velcro closure
- mesh inserts allow visibility of the tools
- a compact storage solution to keep your tools safe
- embroidered STAHLWILLE logo

Benefits.

Made in Germany - STAHLWILLE double open-ended spanner set in sturdy roll-up pouch, 7 pcs., Imperial spanner sizes 1/4"-5/16" chrome-alloy steel, chrome-plated, jaw 15° angle, DIN 3113 Form A, chrome alloy steel, chrome-plated, 96404306.

Extremely resilient and durable - stronger than any screw.

Individual: 4 free compartments in the roll-up tool pouch to add additional spanner sizes.

Slim construction - perfect for working in hard-to-reach places.

High-quality, non-slip surface texture - for safe working even with oily hands.



Technologies and features.



Double-T profile


Our ring, open-ended and combination spanners have an additional recess in the middle of the tool. Similar to the principle of a double-T beam, this provides a tremendous load capacity and maximum strength whilst reducing weight.



Offset Shaft Design

Our spanners are specially designed with additional reinforcement in the load zones where the greatest amount of force is transmitted - namely where the jaw meets the shank - in order to prevent deformation.

Technical drawing.

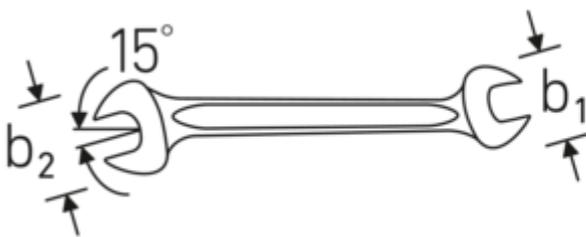

Technical attributes.

Number of tools	7 pcs.
Range	1/4x5/16-1.1/8x1.5/16
Contents	1/4 x 5/16; 3/8 x 7/16; 1/2 x 9/16; 5/8 x 3/4; 11/16 x 13/16; 7/8 x 15/16; 1 1/8 x 1 5/16 "
Alloy	Chrome Alloy Steel

Logistics data.

Depth mm (IFS)	310
Width mm (IFS)	90
Height mm (IFS)	45
WEEE/ElektroG	nicht ear-pflichtig
Length (packaged, mm)	340
Width (packaged, mm)	130

Surface	chrome-plated	Height (packaging, mm)	45
Model No.	10a/7	Volume (packaged, dm3)	1.989 dm3
		Product no.	96404306
		Weight (gross, kg)	1,465
		Weight PAP (kg)	0,000
		Weight PVC (kg)	0,004
		GTIN	4018754080762
		Country of origin AWR	GERMANY
		Region of origin	Nordrhein-Westfalen
		Customs tariff no.	82041100
		Packing standard	1
		Weight (g)	1242 g

Parts list.



91101043
Roll-up tool pouch



40435258
Double open-ended
spanner



40434446
Double open-ended
spanner



40433842
Double open-ended
spanner



40433640
Double open-ended
spanner



40433234
Double open-ended
spanner



40432428
Double open-ended
spanner



40431620
Double open-ended
spanner

Variants.

Product no.	Model No. (ERP)	Description	GTIN
96400301	MOTOR 10a/5 EXTRA	Double open-ended spanner set MOTOR 10a/5 EXTRA 3/8x7/16-15/16x1 5 pcs.	4018754291175
96404306	MOTOR 10a/7	Double open-ended spanner set MOTOR 10a/7 1/4x5/16-1.1/8x1.5/16 7 pcs.	4018754080762
96404307	MOTOR 10a/11	Double open-ended spanner set MOTOR 10a/11 1/4x5/16-1.1/8x1.5/16 11 pcs.	4018754080779

GTIN.



Images.



STAHLWILLE Eduard Wille GmbH

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0

info@stahlwille.de · www.stahlwille.com

© STAHLWILLE Eduard Wille GmbH, Wuppertal