




ENGLISH

Datasheet

8mm Pitch to suit 30mm wide belt
Centre drilled or Pilot Bore
in Steel or Cast Iron with plated Steel Flanges

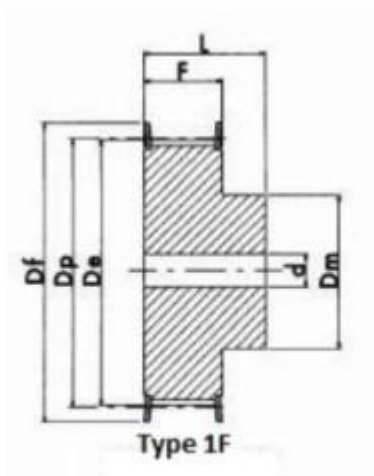



Mat'l	Part Number	No. Teeth	Type	Dp	De	Df	Dm	F	L	Bore	No. Flanges
St.	P22-8M-30F	22	1F	56.02	54.65	60	43	38	48	12	2
St.	P24-8M-30F	24	1F	61.12	59.75	66	45	38	48	12	2
St.	P26-8M-30F	26	1F	66.21	64.85	70	48	38	48	12	2
St.	P28-8M-30F	28	1F	71.30	70.08	75	50	38	48	15	2
St.	P30-8M-30F	30	1F	76.39	75.13	82.5	55	38	48	15	2
St.	P32-8M-30F	32	1F	81.49	80.16	87	60	38	48	15	2
St.	P34-8M-30F	34	1F	86.58	85.22	91	66	38	48	15	2
St.	P36-8M-30F	36	1F	91.67	90.30	97	70	38	48	15	2
St.	P38-8M-30F	38	1F	96.77	95.39	102	75	38	48	15	2
St.	P40-8M-30F	40	1F	101.86	100.49	106	75	38	48	15	2
St.	P44-8M-30F	44	1F	112.05	110.67	120	75	38	48	15	2
St.	P48-8M-30F	48	1F	122.23	120.86	128	75	38	48	15	2
St.	P56-8M-30F	56	2F	142.60	141.23	150	90	38	48	15	2
St.	P64-8M-30F	64	2F	162.97	161.60	168	90	38	48	15	2
St.	P72-8M-30F	72	2F	183.35	181.97	192	95	38	48	15	2
C.I.	P80-8M-30	80	3	203.72	202.35	-	100	38	48	15	-
C.I.	P90-8M-30	90	3	229.18	227.81	-	100	38	48	15	-
C.I.	P112-8M-30	112	4	285.21	283.83	-	100	38	48	18	-
C.I.	P144-8M-30	144	4	366.69	365.32	-	100	38	48	20	-
C.I.	P168-8M-30	168	4	427.81	426.44	-	100	38	48	20	-
C.I.	P192-8M-30	192	4	488.92	487.55	-	100	38	48	20	-

ENGLISH