

Batten LED Link

BATTEN LED TWIN LINK 55W 1500 840
0045147



Range Features

- Slimline versatile LED waterproof batten
- Linkable (through wiring)
- IP65/IK08 Protection
- Alternative to 2x58W LFL Twin Batten
- Instant light and high lumen efficacy of 98lm/W
- Long lifetime: 30,000hrs
- Available in 3000K or 4000K

PRODUCT OVERVIEW

Beam angle(°)	120
Certifications	CE
Colour temperature (K)	4000
Colour	White
CRI (Ra)	80
EAN code	5410288451473
Luminous flux (lm)	5410
Housing	Polycarbonate
IK rating	IK08
IP rating	IP65
Light colour	Cool White
LOR (%)	100
Mount	Surface Mounted
Ordering number	0045147
Efficacy (Rated) (lm/w)	98
Average life (Rated) (h)	30000
Technology	LED
Voltage (V)	220-240
Colour consistency (SDCM)	6 Step

DATA TABLE

Optical data

Beam angle(°)	120
Colour temperature (K)	4000
CRI (Ra)	80
Distribution type	Direct
Luminous flux (lm)	5410
Light colour	Cool White
LOR (%)	100

Batten LED Link

BATTEN LED TWIN LINK 55W 1500 840

0045147

Colour consistency (SDCM) 6 Step

General data

Certifications	CE
EAN code	5410288451473
General application	Consumer Residential; Logistics and Industry
Housing	Polycarbonate
Mount	Surface Mounted
Ordering number	0045147
Range features	Slimline versatile LED waterproof batten Linkable (through wiring) IP65/IK08 Protection Alternative to 2x58W LFL Twin Batten Instant light and high lumen efficacy of 98lm/W Long lifetime: 30,000hrs Available in 3000K or 4000K
Product name	BATTEN LED TWIN LINK 55W 1500 840
Average life (Rated) (h)	30000
Technology	LED
Product features	The new Batten LED Link is a versatile range of slimline LED waterproof luminaires that provide an ideal solution for interior and exterior applications such as workshops, garages and outdoor covered spaces. The improved design allows the luminaire to be easily linked to another luminaire through an IP65 rated connector. The range has been increased to include a higher lumen output offer with a Twin Batten LED Link delivering a performance of up to 5410lm (93lm/W). Available in 1200mm and 1500mm lengths (approx.) - the product can be a slimline replacement for single and twin 36W/58W fluorescent waterproof battens.

Physical data

Colour	White
Diffuser finish	Opaque
Height (mm)	54
IK rating	IK08
IP rating	IP65
Lamp included	No
Length (mm)	1553
Width (mm)	80

Electrical data

Drive current (mA)	500
Electrical protection	CLASS II
Efficacy (Rated) (lm/w)	98
Ta rating (°C)	-10 to +40

Batten LED Link

BATTEN LED TWIN LINK 55W 1500 840
0045147



Total power consumption (W)

55




Voltage (V)

220-240

PHOTOMETRY

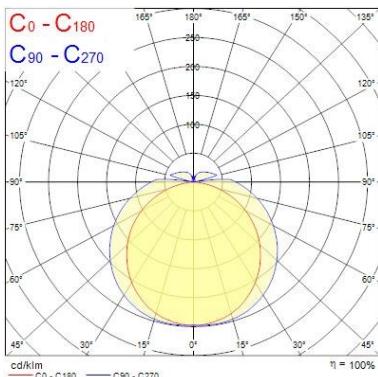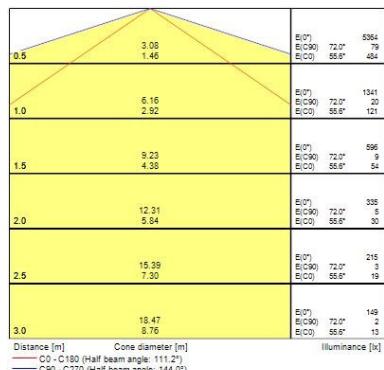

TECHNICAL DRAWINGS

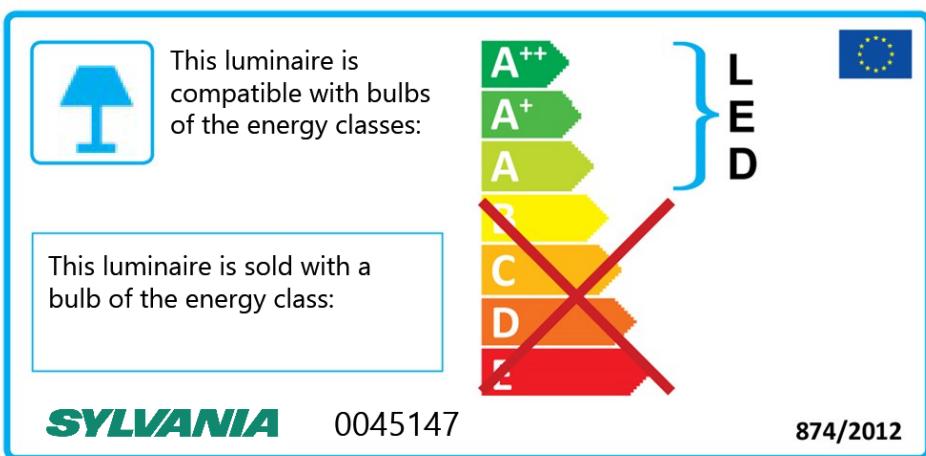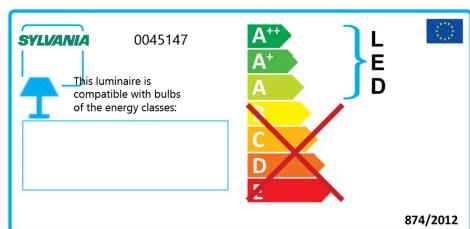 

Batten LED Link

BATTEN LED TWIN LINK 55W 1500 840

0045147