


DEP09S365TLF - D-Subminiature :
PCB Connector 09 Way Socket
Straight Spill, without Accessory

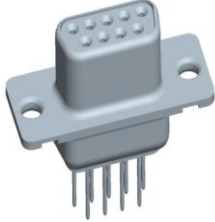

www.fci.com

Specifications

Approvals / Certifications	
Approvals / Certifications	Recognized (File E 118235)
Dimensional	
Size (Shell)	E
Electrical	
Current rating	7.5A per Contact
Resistance (Contact)	< 7.3 milli ohms
Voltage rating	1000V rms at 50 Hz
Voltage rating (DWV - Dielectric withstanding)	1000V rms
General	
Contact type	Signal
Gender	Socket
Number of contacts (Total)	9
Product Type	Connector
Termination Style	PCB
Mechanical	
Durability (Mating cycles)	High Perf (>500 Mating Cycles)
Extraction force (Signal)	0.3N min. per Contact
Insertion force (Signal)	5N max. per Contact
Mounting	
Mounting options	No Accessories
Other Features	
Most Popular Configuration	Yes

Category Path	/Product type/Input-Output Connectors/D-Subminiature/D-Sub High Performance Product type/Input-Output Connectors/D-Subminiature/D-Sub High Performance
Physical	
Plating (Contact)	Gold over Nickel
Plating (Shell)	Matte Tin
Plating (Termination)	Matte Tin over Nickel
Temperature (Operating - range)	-55°C to +125°C

