


## FEATURES

- **Durable Polyamide Nylon Construction:** Provides long-lasting performance and resistance to wear and tear.
- **8 mm Shackle Diameter:** Suitable for a variety of pneumatic applications, ensuring compatibility with standard fittings.
- **Single Lock Design:** Simplifies the lockout process, making it easy to use and manage.
- **ISO 9001, ISO 14001, OHSMS 45001 Certified:** Meets international standards for quality, environmental management, and occupational health and safety.
- **Bright Red Colour:** Enhances visibility, ensuring the lockout device is easily identifiable.

## RS PRO 8 mm Pneumatic Lockout, Red Polyamide Nylon

RS Stock No: 710-509

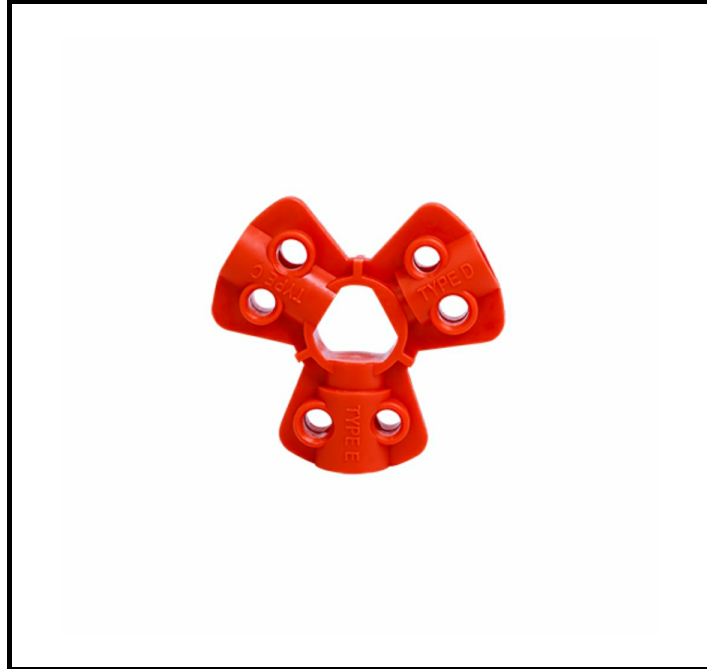

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

This RS PRO pneumatic lockout device is designed to securely isolate pneumatic energy sources, ensuring safety during maintenance and repair operations. Made from durable red polyamide nylon, it is ideal for preventing accidental activation of pneumatic systems, enhancing workplace safety.

## General Specifications

Colour	Red
Number of Locks	1
Product Type	Lockout
Sub Type	Pneumatic Lockout

## Mechanical Specifications

Material	Polyamide Nylon
Shackle Diameter	8 mm

## Approvals

Standards/Approvals	ISO 9001, ISO 14001, OHSMS 45001, UKAS 0043
---------------------	---