



1230979 PIEZO INDICATOR


Specifications	1230979
Rated voltage	12VDC
Operating voltage	3~20VDC
Rated current*	≤15mA
Sound output at 10cm*	≥95dB
Resonant frequency	3400±500Hz
Tone	Continuous
Operating temperature	-20~+70°C
Storage temperature	-40~+85°C
Weight	4g

*Value applying at rated voltage (DC)

All data at 25°C unless otherwise specified

Features

- ROHS compliant
- Black in colour
- With internal drive circuit
- Housing material: Noryl
- Pin material: Red copper
- Wave solder and wash not allowed

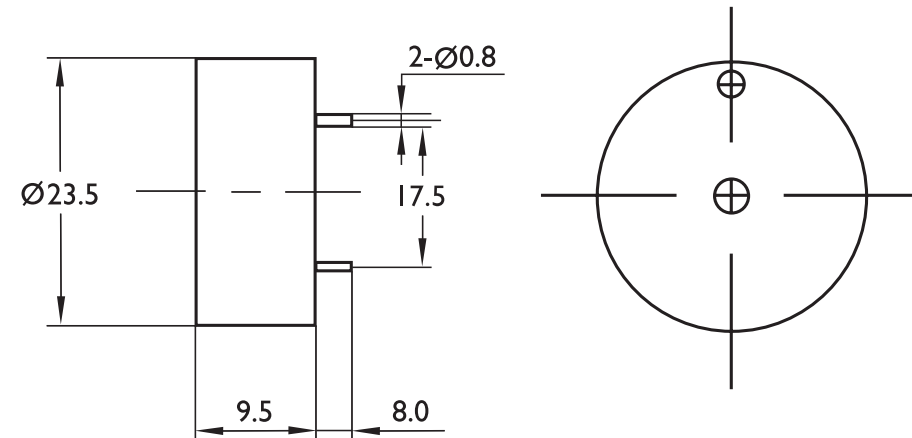

Dimensions Unit: mm Tolerance: ± 0.5 mm