



CorePro LEDtube

CorePro LEDtube 600mm 10W 840 C

The CorePro LEDtube is an affordable LED solution suitable for replacing T8 fluorescent lamps. The product provides a natural lighting effect for use in general lighting applications, as well as instant energy savings – an environmentally friendly solution.

Product data

• General Characteristics

Cap-Base	G13
Life to 70% lumen maintenance	30000 hr

• Light Technical Characteristics

Colour Code	840
Beam Angle	140 D
Correlated Colour Temperature	4000 K
Luminous Flux	800 Lm
Colour rendering index	80

• Electrical Characteristics

Wattage	10 W
Voltage	220-240 V
Power Factor	0.9 (min) -

• Temperature Characteristics

T-case maximum	55 (max) C
Operating temperature	-30 (min), 45 (max) C
T-Storage	-40 (min), 65 (max) C

• Product Dimensions

Length A1	588.5 mm
Fixing Hole Distance	595.5 mm
A2 Length	

Length A3	602.5 mm
Mounting hole diameter	25.68 mm
Circular outline dimension	28 mm

• Approval & Application Chars

VDE marking	No
CE marking	Yes
UL certificate	No
RoHS compliance	Yes
KEMA Keur certificate	Yes


• Product Data

Order code	669715 00
Full product code	871829166971500
Full product name	CorePro LEDtube 600mm 10W 840 C
Order product name	CorePro LEDtube 600mm 10W 840 C
Pieces per pack	1
Packing configuration	10
Packs per outerbox	10
Bar code on pack - EAN1	8718291669715
Bar code on outerbox - EAN3	8718291669722
Logistic code(s) - 12NC	929000296832
Net weight per piece	0.210 kg



PHILIPS
sense and simplicity

Dimensional drawing

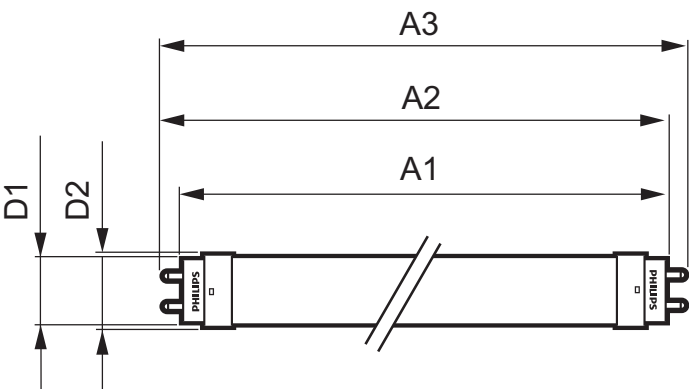

CorePro LEDtube 600mm 10W 840 C

Product	A1 (Norm)	A2 (Norm)	A3 (Norm)	D1 (Norm)	D2 (Norm)
TLED 600mm 10W740 T8	588.5	595.5	602.5	25.68	28



G13

