


VersaTouch®

92-465

Nitrile Disposable Glove

Dark blue gloves offering a reliable grip for food service jobs

- **Ideal for food handling:** VersaTouch® 92-465 dark blue nitrile gloves are food handling-compliant and well suited for a wide range of food processing tasks
- **Textured fingertips:** The fingertips offer good flexibility and tear strength
- **Smart packaging:** Polybag packaging reduces risks of contamination, particularly in wet environments

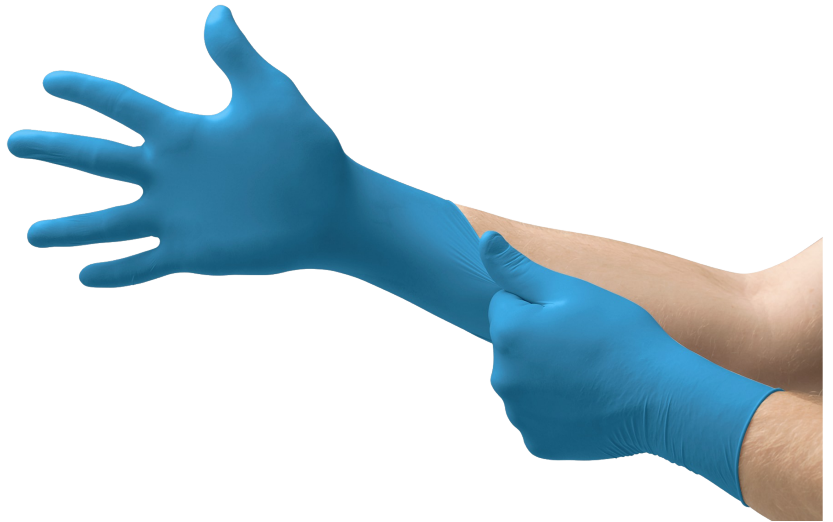

Industries

- Food Processing

Recommended For

- All food processing, applications that have food contact

TECHNICAL DATA SHEET

	Product Information
External Glove Surface	Textured Fingers
Audit Standards	ISO 9001
Product Certification	Category III, EN ISO 21420:2020, EN ISO 374-1:2016 Type B JKT, EN ISO 374-5:2016 Virus, FDA21 CFR 177-2600-US Food Contact Approved, EU Food Contact Approved, ISO 9001, UKCA
Packaging Overview	100 gloves per polybag; 10 polybags per case; 1000 gloves per Master polybag
Storage Instructions	Keep out of direct sunlight; store in a cool and dry place. Keep away from sources of ozone or ignition.
Country Of Origin	Malaysia
Product Segmentation	Multi-Purpose
Antistatic	Yes EN1149
Silicone Free	Yes
Vulcanization Chemical Accelerators	Zinc Dibutyldithiocarbamate (ZDBC) <i>Only a very small number of users may be sensitive to this ingredient(s) and hence may develop irritant and/or allergic contact reactions.</i>

PHYSICAL PROPERTIES

	Typical Values		Testing Method
Length (mm/inches)	240 / 9.5		ASTM D3767,EN 420
Freedom from Holes (Inspection level I)	1.5 AQL		ASTM D5151,EN 455-1
Palm Thickness (mm/mils)	0.11 / 4.3		ASTM D3767,EN 420
Finger Thickness (mm/mils)	0.15 / 6.3		ASTM D3767,EN 420
	BEFORE AGING	AFTER AGING	
Ultimate Tensile Strength (MPa)	≥ 16	≥ 14	ASTM D412 & D573
Elongation at Break (%)	≥ 500	≥ 400	ASTM D412

ORDERING INFORMATION

Size	S (6.5 - 7)	M (7.5 - 8)	L (8.5 - 9)	XL (9.5 - 10)
Product Code	92465070	92465080	92465090	92465100

Performance Standards and Regulatory Compliance



For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region Ansell Healthcare Europe NV T: +32 (0) 2 528 74 00 F: +32 (0) 2 528 74 01 Asia Pacific Region MY +603 8310 6688 apac.medical@ansell.com CN: +86 21 38275000 infochina@ansell.com JP: +813 5549 8151 info.medical.jp@ansell.com	North America Region Ansell Healthcare Products LLC T: +1 800 800 0444 F: +1 800 800 0445 Latin America & Caribbean Region BR +55 (11) 3356-3100 latam.medical@ansell.com MX: +52 442 296 2050 latam.medical@ansell.com CO: +57 1 288 3247 latam.medical@ansell.com	Australia Ansell Limited T: +61 1800 337 041 F: +61 1800 803 578 Russia Ansell PYC Ten. +7 495 258 13 16
--	---	--

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending; www.ansell.com/patentmarking © 2025 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

