

3NC1425 SITOR CYL. FUSE 25A 690V A.C. AR

SITOR CYLINDRICAL FUSE LINK AR 25 A, 660 V AC/700 V DC



Similar to image

Technical data:

Current / for AC / rated value	A	25
Supply voltage		
• for AC / rated value	V	690
• for DC	V	500
Switching capacity current		
• in accordance with IEC 60947-2 / rated value	kA	200
Design of an identification indicator		others
Ambient temperature	°C	-20...+50

Certificates/approvals:

General Product Approval		Declaration of Conformity	
<input checked="" type="checkbox"/> CSA	ROSTEST	<input checked="" type="checkbox"/> UL	Manufacturer

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/lowvoltage/mall>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)


<http://support.automation.siemens.com/WW/view/en/3NC1425/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC1425

CAx-Online-Generator

<http://www.siemens.com/cax>

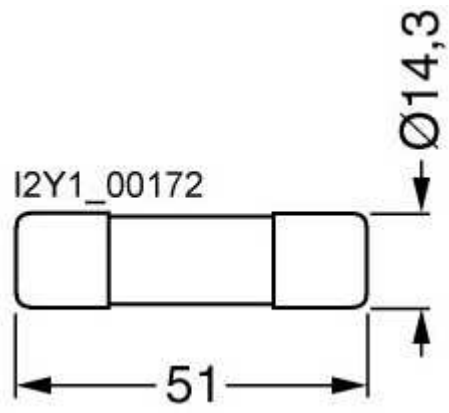

last change:

Mar 10, 2012