



Connectors > Audio & Video Connectors > USB Connectors



USB Adapter Type: **A/B**

USB Version: **2.0**

Connector Profile: **Mini**

Connector & Housing Type: **Receptacle**

Number of Ports: **1**

Features

Product Type Features

Integral Locking Latch	Without
USB Adapter Type	A/B
USB Version	2.0
Connector & Housing Type	Receptacle
Connector System	Cable-to-Board
Connector & Contact Terminates To	Printed Circuit Board
USB Connector Type	Mini USB 2.0 Type-AB

Configuration Features

Number of Ports	1
Number of Positions	5

Body Features

Shell Plating Material	Nickel
Offset	0 mm
Connector Profile	Mini



Contact Features

Contact Mating Area Plating Material Thickness	.76 µm[29.92 µin]
Contact Mating Area Plating Material	Gold (Au)
Contact Current Rating (Max)	1 A

Termination Features

Termination Post & Tail Length	1.15 mm[.045 in]
Termination Method to PCB	Surface Mount

Mechanical Attachment

Locking Feature	With
PCB Mount Alignment Type	Locating Posts
PCB Mount Location	Top
PCB Connector Seating	Flush
PCB Mount Retention Type	Hold-Down
Connector Mounting Type	Board Mount

Housing Features

Housing Color	Black
Housing Material	PA 9T
Body Orientation	Right Angle
Centerline (Pitch)	.8 mm[.031 in]

Dimensions

PCB Thickness (Recommended)	1.57 mm[.062 in]
-----------------------------	------------------

Usage Conditions

Soldering Temperature (Max)	260 °C[500 °F]
Mating Cycles (Max)	5000
Operating Temperature Range	-40 – 85 °C[-40 – 185 °F]

Operation/Application

Halogen Free	No
Circuit Application	Power & Signal

Industry Standards

Industry Standard	USB 2.0
Moisture Sensitivity Level	1
UL Flammability Rating	UL 94V-0



Packaging Features

Packaging Quantity	700
Packaging Method	Tape & Reel

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Reflow solder capable to 260°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




TE Part # 1734205-1
MINI USB, TYPE B, PLUG. CABLE-KIT



TE Part # 1496476-1
STD USB-A TO MINI-B ASSY, 1M



TE Part # 1929690-1
USB CABLE, USB A to Mini USB,Blue

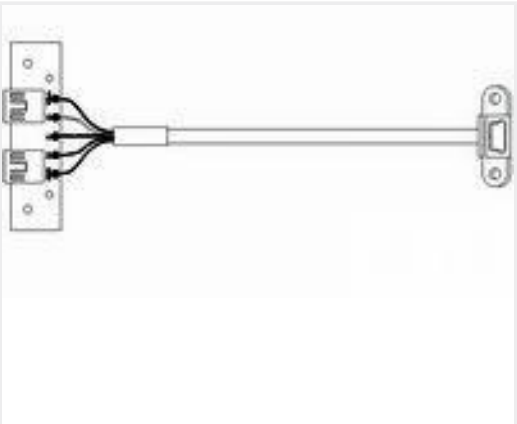

TE Part # 2009025-1
Hook USB Assembly

Customers Also Bought





TE Part #1601097-3
TAB,2.79X0.81,STD,SMZ




TE Part #1-1452424-1
BLIND PLUG FOR MCON 1.2 CB (0,




TE Part #1601046-2
WIRE2WIRE,STD,SMZ



TE Part #2-338069-0
MICRO-MATCH SMD FTE

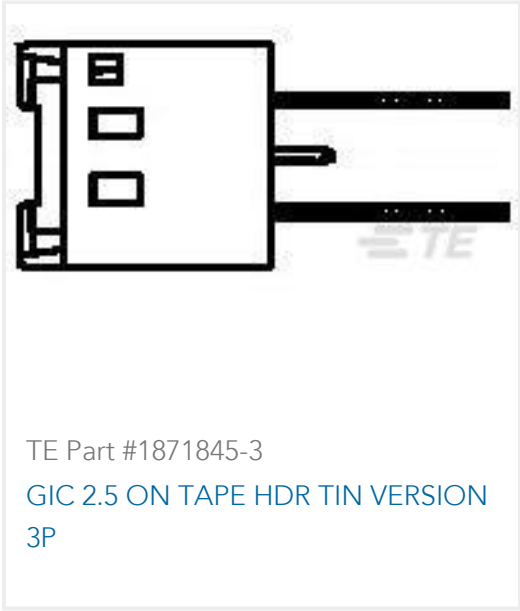

TE Part #1871845-3
GIC 2.5 ON TAPE HDR TIN VERSION 3P

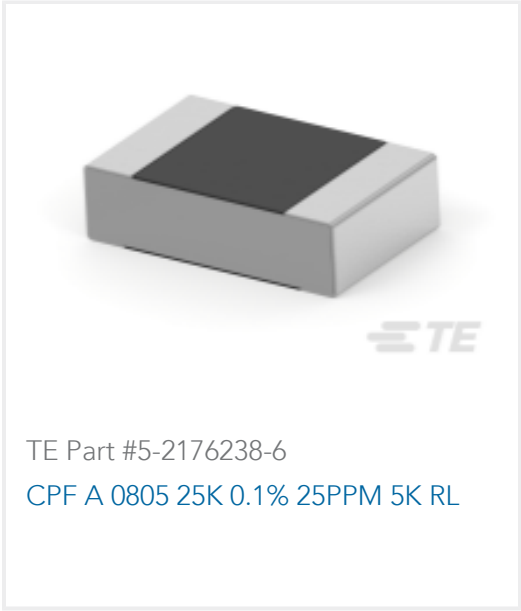

TE Part #5-2176238-6
CPF A 0805 25K 0.1% 25PPM 5K RL



TE Part #5-1676480-0
CRG0402 1% 330R



TE Part #5552744-1
ASSY,RCPT,64 POSN,RTANG,PCB



TE Part #185534-3
26pos MQS .63 header 90deg



TE Part #5-1376492-3
2.5MM SIGNAL MATE CONN ON TAPE

Documents

Product Drawings
Mini USB AB R/A,Rcpt,SMT,T&R
English

CAD Files
Customer View Model
ENG_CVM_CVM_1734328-2_D.2d_dxf.zip
English
3D PDF
3D
Customer View Model
ENG_CVM_CVM_1734328-2_D.3d_igs.zip
English
Customer View Model
ENG_CVM_CVM_1734328-2_D.3d_stp.zip
English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.

Product Specifications



Product Specification

English