


# silencer

## U-1/8-I

Part number: 3670

FESTO

For reducing noise and avoiding contamination at the exhaust ports of pneumatic components.

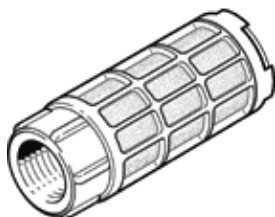

## Data sheet

Feature	Value
Assembly position	Any
Operating pressure	0 ... 10 bar
Flow rate to atmosphere	2,050 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Sound pressure level	76.5 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	3.6 g
Pneumatic connection	G1/8
Material of silencer insert	PE
Materials note	Free of copper and PTFE Conforms to RoHS