


Magnetic Ballasts for HID Lamps

Magnetic Ballast Electrical Data

Lamp Watts (W)	150
Lamp Current (A)	1.8
Input Voltage at 50Hz	230/240
Circuit Watts (W)	176
Running Current (A)	0.8
Delta T (°C)	70/75
tw (°C)	140
Thermal cut out °C (± 5°C)	160
Capacitor Value (µf)	20
Capacitor Voltage (V)	250
Energy Efficiency Index (EEI)	A3

Physical Data

Dimensions (LxWxH mm)	150x69x56
Fixings (mm)	133x141
Weight (kg)	2.3

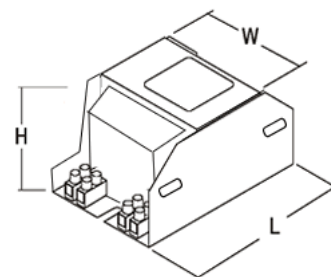

Ballast Diagram

Revision: 15-07-2013

See page 2 for product notes



Product Code: HSA15223221

Magnetic Ballasts for HID Lamps

Notes:

Additional fixings 53x126-139mm and side fixings 125-139mm