


1310166 DHRS-40-A Radial gripper - Series: All

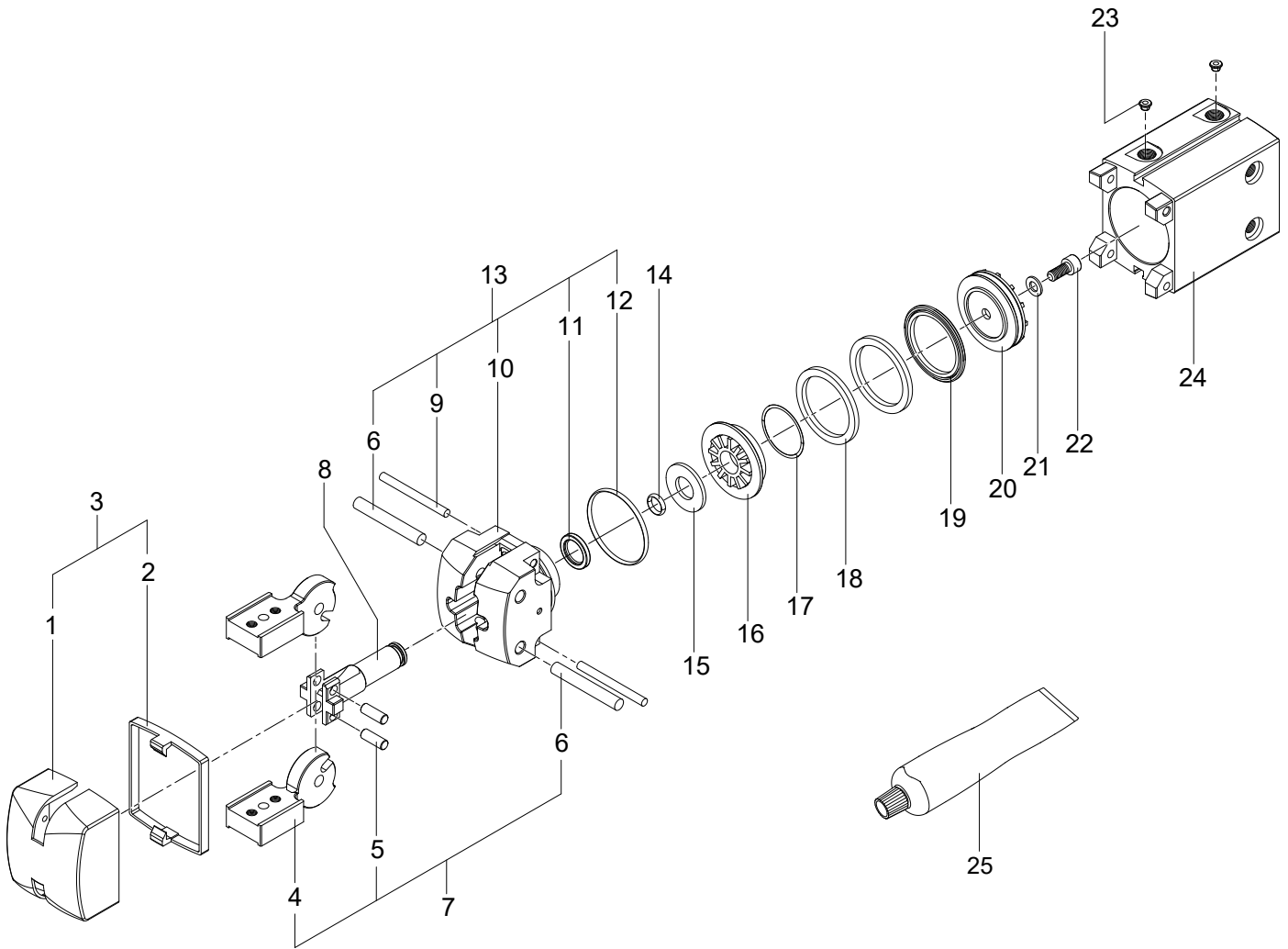

## 1310166 DHRS-40-A Radial gripper - Series: All

| Pos.    | Part no. | Type                                          | Note                                                                                            | Qty. | Unit |
|---------|----------|-----------------------------------------------|-------------------------------------------------------------------------------------------------|------|------|
| A       | 1564141  | DHRS-40-A<br>Set of wearing parts             | Spare parts: 11, 12                                                                             | 1    | PC   |
| 1       |          |                                               | Not available separately, see position 3                                                        | 1    | PC   |
| 2       |          |                                               | Not available separately, see position 3                                                        | 1    | PC   |
| 3       | 1564140  | DHRS-40-A<br>Covering                         |                                                                                                 | 1    | PC   |
| 4       |          |                                               | Not available separately, see position 7                                                        | 2    | PC   |
| 5       |          |                                               | Not available separately, see position 7+998                                                    | 2    | PC   |
| 6       |          |                                               | Not available separately, see position 7+13+998+999                                             | 2    | PC   |
| 7       | 1564138  | DHRS-40-A<br>Gripper jaw                      |                                                                                                 | 1    | PC   |
| 8       |          |                                               | Not available separately, see position 998                                                      | 1    | PC   |
| 9       |          |                                               | Not available separately, see position 13+998+999                                               | 2    | PC   |
| 10      |          |                                               | Not available separately, see position 13                                                       | 1    | PC   |
| 11      |          |                                               | Not available separately, see position 13+999<br>Grease using during assembly. See position 25  | 1    | PC   |
| 12      |          |                                               | Not available separately, see position 13+999<br>Grease using during assembly. See position 25  | 1    | PC   |
| 13      | 1564139  | DHRS-40-A<br>Jaw guide                        |                                                                                                 | 1    | PC   |
| 14      |          |                                               | Not available separately, see position 998+999<br>Grease using during assembly. See position 25 | 1    | PC   |
| 15      |          |                                               | Not available separately, see position 998+999                                                  | 1    | PC   |
| 16      |          |                                               | Not available separately, see position 998                                                      | 1    | PC   |
| 17      |          |                                               | Not available separately, see position 998+999<br>Grease using during assembly. See position 25 | 1    | PC   |
| 18      |          |                                               | Not available separately, see position 998                                                      | 1    | PC   |
| 19      |          |                                               | Not available separately, see position 998+999<br>Grease using during assembly. See position 25 | 1    | PC   |
| 20      |          |                                               | Not available separately, see position 998                                                      | 1    | PC   |
| 21      |          |                                               | Not available separately, see position 998                                                      | 1    | PC   |
| 22      |          |                                               | Not available separately, see position 998                                                      | 1    | PC   |
| 23      |          |                                               | Not available                                                                                   | 2    | PC   |
| 24      |          |                                               | Not available                                                                                   | 1    | PC   |
| 25      | 397394   | LUB-M1-SILIKONFREI-10ML<br>Lubricating grease |                                                                                                 | 1    | PC   |
| 99<br>8 | 1564137  | DHRS-40-A<br>Piston module                    |                                                                                                 | 1    | PC   |