




Datasheet

Stock No: 123-3557

ENGLISH

RS Pro Analogue Oscilloscope

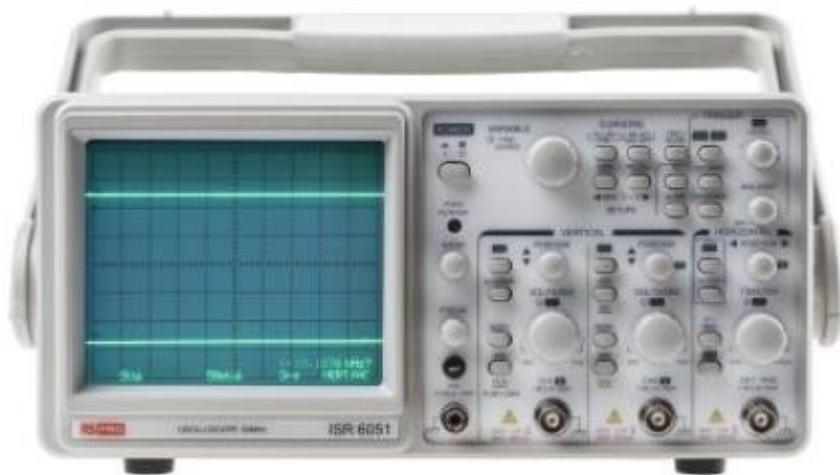

Description:

ISR6051 analogue oscilloscopes have a remarkable combination of performance, compact design and resolution in bandwidths of 30MHz and 50MHz. Coupled with various trigger modes, waveforms can be acquired and observed in a number of diverse applications. Elusive signal details can be revealed using the ALTMAG function to magnify signals (x5, x10x 30). The on-screen cursor readout function and 6 digit frequency counter allow signals to be tested conveniently, making the ISR6051 oscilloscope essential tool for any professional engineer.

Features:

2 Channels, 4 Traces:

DC~50MHz Bandwidth

- * Vertical Sensitivity : 1mV/div ~ 20V/div
- * CRT Readout
- * Cursor Measurement, 6 Digit Frequency Counter, 10 sets Memory for Front Panel Setting Save & Recall
- * ALT MAG Function (x 5, x 10, x 20)
- * Vertical Mode Triggering
- * TV Synchronization
- * CH1 Signal Output, Z- axis Input
- * Buzzer Alarm & LED Indicators
- * Compact size(275Wx130Hx370Dmm) and Front Panel Layout Groups for Easy to Use