


200 (+)1X75 Ball-Grip VDE Insulated Screwdriver

Elastic grip assures reliable tightening.

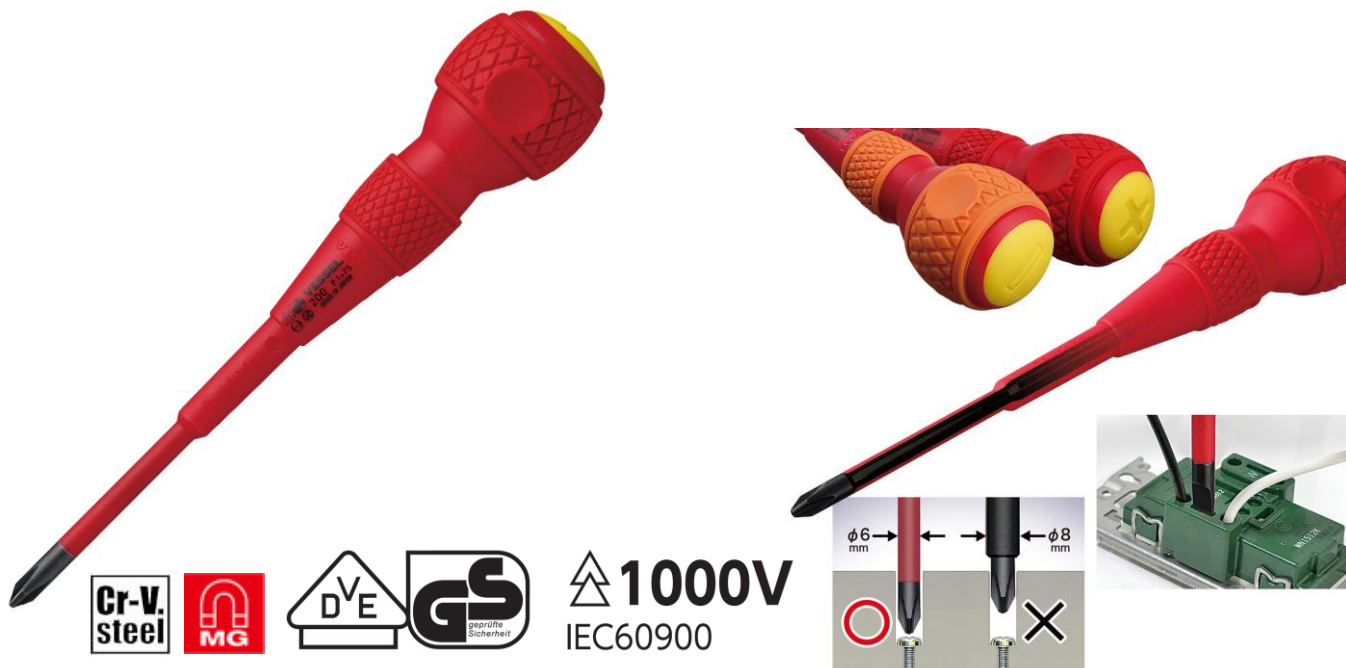

- Insulated Screwdrivers Series 1000V certified by VDE (IEC60900), International certification authority.
- Shank cover prevents short circuits. Thin shank is convenient for operating on terminal blocks.
- Cushion grip is marked + - for quick identification.
- The original ergonomic BALL GRIP handle enable quick and power driving.
- Unique ergonomic form reduces muscle fatigue by 20%
- Transmits ample tightening force to screw.
- High precision black point magnetic tip.

PRODUCT SPECIFICATION

Index	Modèle	Product	mm	mm	mm	mm	mm	mm	Inner C/T unit	Outer C/T unit	EAN
125841	200 (-)5X75	BALL GRIP VDE 1000V -5.0 75mm	5.0	0.8	75	5	32	150	6	60	4907587007544
125842	200 (-)6X100	BALL GRIP VDE 1000V -6.0 100mm	6.0	1.0	100	6	41	189	6	60	4907587007551
125843	200 (-)6X150	BALL GRIP VDE 1000V -6.0 150mm	6.0	1.0	150	6	41	239	6	60	4907587007568
125844	200 (+)1X75	BALL GRIP VDE 1000V PH1 75mm		PH1	75	5	32	150	6	60	4907587007575
125845	200 (+)2X100	BALL GRIP VDE 1000V PH2 100mm		PH2	100	6	41	189	6	60	4907587007582
125846	200 (+)2X150	BALL GRIP VDE 1000V PH2 150mm		PH2	150	6	41	239	6	60	4907587007599
125847	200 (+)3X150	BALL GRIP VDE 1000V PH3 150mm		PH3	150	6	41	239	6	60	4907587007605
125861	200 PZ1X75	BALL GRIP VDE 1000V PZ1 75mm		PZ1	75	5	32	150	6	60	4907587027764
125862	200 PZ2X100	BALL GRIP VDE 1000V PZ2 100mm		PZ2	100	6	41	189	6	60	4907587027771
125863	200 PZ2X150	BALL GRIP VDE 1000V PZ2 150mm		PZ3	150	6	41	239	6	60	4907587027856