



1262H.SR - Non sparking German style club hammer



Description:

- Special non sparking and anti-magnetic Copper-Beryllium alloy.
- For safety purposes, FACOM uses wooden handles to prevent any risk of sparks. This is not the case of certain bi-material plastic handles.
- To avoid any risk of sparks, the design of the hammer heads is specific, without sharp edges.

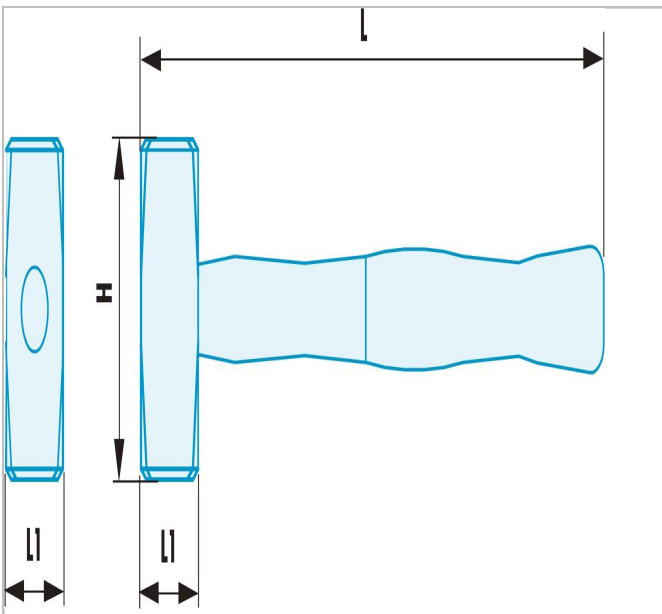

	Length L [mm]	Length L1 [mm]	Height H [mm]	Weight [g]
1262H.100SR	250.0	38.0	94.0	1300.0
1262H.150SR	250.0	42.0	115.0	1800.0
1262H.200SR	250.0	46.5	125.5	2300.0
1262H.400SR	800.0	58.0	165.0	4900.0
1262H.500SR	800.0	62.0	178.0	5900.0
1262H.50SR	250.0	29.0	80.0	650.0