



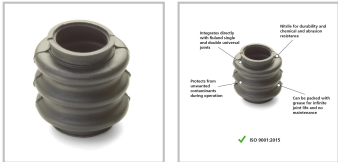

UBOOT16/25-NI-KIT

Ruland UBOOT16/25-NI-KIT, Universal Joint Boot for 0.995" (25.27mm) OD,
Nitrile, Triple Bellows

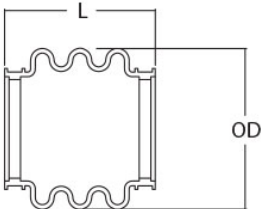

Description

Ruland UBOOT16/25-NI-KIT is a Nitrile boot cover kit for universal joints with an OD of 0.995" or 25.27mm. This boot cover protects the universal joint from unwanted contaminants such as dust and can be packed with grease for lubrication retention. It comes with zip ties that seat into grooves on each yoke ensuring a tight seal. UBOOT16/25-NI-KIT is made from Nitrile for durability and abrasion resistance that helps protect the boot from being damaged and grease leaking out or contaminants entering the joint. Nitrile also has high resistance to petroleum-based oils and fuels, silicone greases, hydraulic fluids, water, and alcohol which are commonly present in operating environments where this universal joint is used. It is designed to fit with single and double universal joints beginning with US16, USSK16, UD16, UDSK16, MUS25, and MUSSK25.

Product Specifications

Boot Outer Diameter (OD)	1.50 in (38.1 mm)	Length (L)	1.500 in (38.1 mm)
Bellows	Triple	Material Specification	Nitrile
Manufacturer	Belden Universal	Country of Origin	USA
Weight (lbs)	0.016000	UPC	634529289358
Tariff Code	8483.60.4000	UNSPC	25173810
Note 1	Performance ratings are for guidance only. The user must determine suitability for a particular application.		