


Masking frame 3VA12 (250 A), 3-pole, fixed-mounted, plug-in design, 8US setup, drive: direct, front-mounted rotary operator, motorized operating mechanism, RCD: without, H: 400 mm W: 800 mm

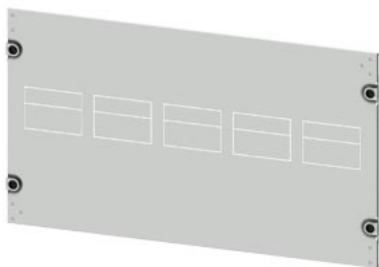

Model	
product brand name	SIVACON S4
design of the surface	powder-coated
height	400 mm
width	800 mm
depth	10 mm
installation width for cabinet installation	800 mm
mounting height for device equipment can be used	400 mm
material	sheet-steel
reference code according to IEC 81346-2	UC

Approvals Certificates	
General Product Approval	other

[Miscellaneous](#)



[Confirmation](#)

Environment

[Environmental Conformations](#)

[Environmental Conformations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ2040-8BA23>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8PQ2040-8BA23>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ2040-8BA23

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

