


PXP4013/08S/PC Datasheet

Product Name // Rear Panel Mount PCB Mount Connector
PXP4013 Series 8 Contact Socket

 [View Product Page](#)

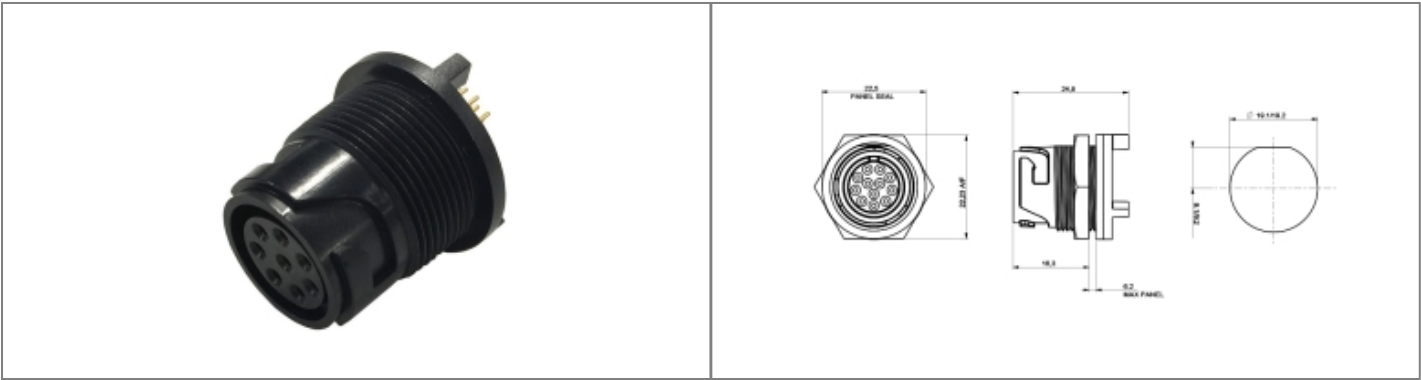

// Product Description:

- ⬢ Rear Panel Mount Connector
 - ⬢ Sealed to IP66, IP68, IP69K when mated with compatible connector
 - ⬢ Single hole fixing
 - ⬢ Pin or Socket
 - ⬢ 2, 3, 4, 6, 8, 10 or 12 Contact
- ⬢ Choice of:
 - ⬢ Cable connector version uses Crimp or Solder Contacts (supplied separately; use 13A/10A for 2, 3 Contact, 8A/5A for 4, 6, 8 Contact, 3A/3A for 10, 12 Contact), contact insertion and crimp tools available separately
 - ⬢ PCB mount version (part codes suffixed /PC) use straight PCB spills and are supplied complete with pre-loaded gold plated contacts
 - ⬢ PXP4083 Sealing Cap available separately to maintain IP rating of unmated connectors
 - ⬢ Mate with Flex Cable Connectors PXP4010, PXP4011

// General Information:

Product Display Title:	Rear Panel Mount Connector
Product Family:	Circular Power Connectors
Product Series:	4000 Series Buccaneer
Approvals:	CSA
Body Material:	Polycarbonate/Polybutylene Terephthalate (PC/PBT)
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	5A
Diameter Over Coupling Ring Mm:	19.7mm
Flamability Rating:	UL94V-0
Function:	Rear Panel Mount PCB Mount Connector
Ip Rating:	IP66
Max Operating Temperature:	+120°C
Min Operating Temperature:	-40°C
Number Of Contacts:	8 Contacts
Voltage Max:	320V

// Product PDF Links

-  [4000 Series power connectors...](#)
-  [4000 Series power connectors...](#)

// Product 3D CAD Model Links

-  [PXP4013/08S/PC3D CAD Model](#)

// Product Certificate Links

-  [UL & CSA EN214792 - 4000 Series...](#)
-  [VDE Certificate - 4000 Series...](#)
-  [IP68 Test Certificate - 4000...](#)
-  [IP69X Test Certificate - 4000...](#)
-  [Salt Spray Test Certificate - 4000...](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)