



# FLEXI-BNC90-433


- 1/4 Wavelength Whip Antenna
- Rugged Flexible Plastic Finish.
- Available as BNC, SMA-Plug, M4 Screw Fixing
- Omni-Directional Design
- 50ohm Impedance
- Operating Temp -30 to +60°C
- Insulation resistance 500MΩ@500Vdc



## Applications

- General Low Power Radio
- M2M Applications


## Mechanical Dimensions

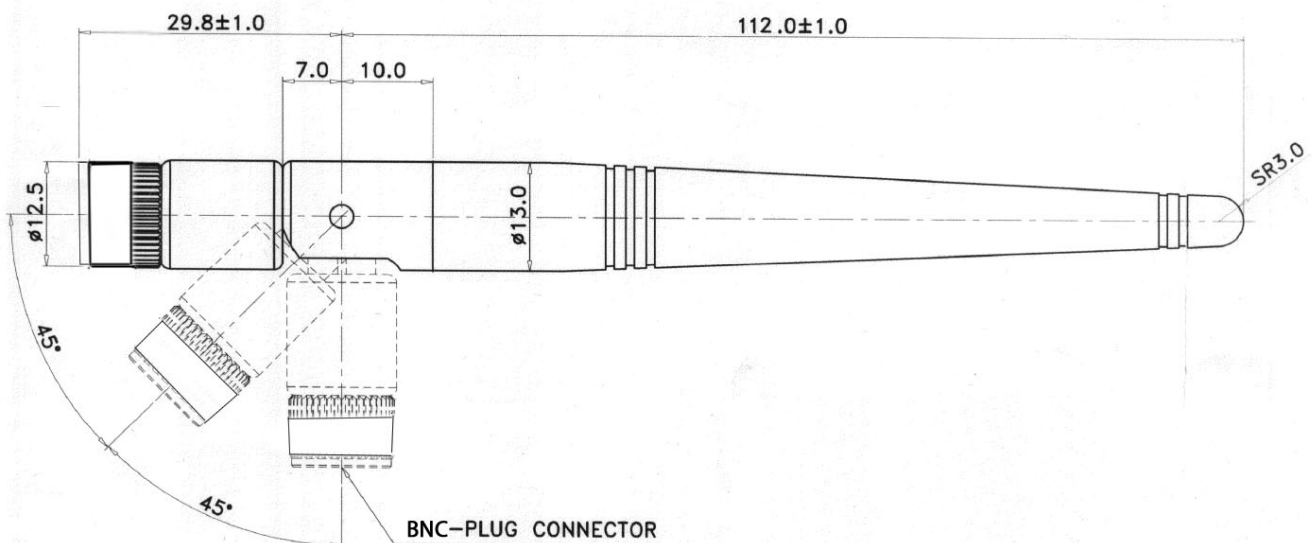



# FLEXI-BNC90-433

## Performance / VSWR Plot

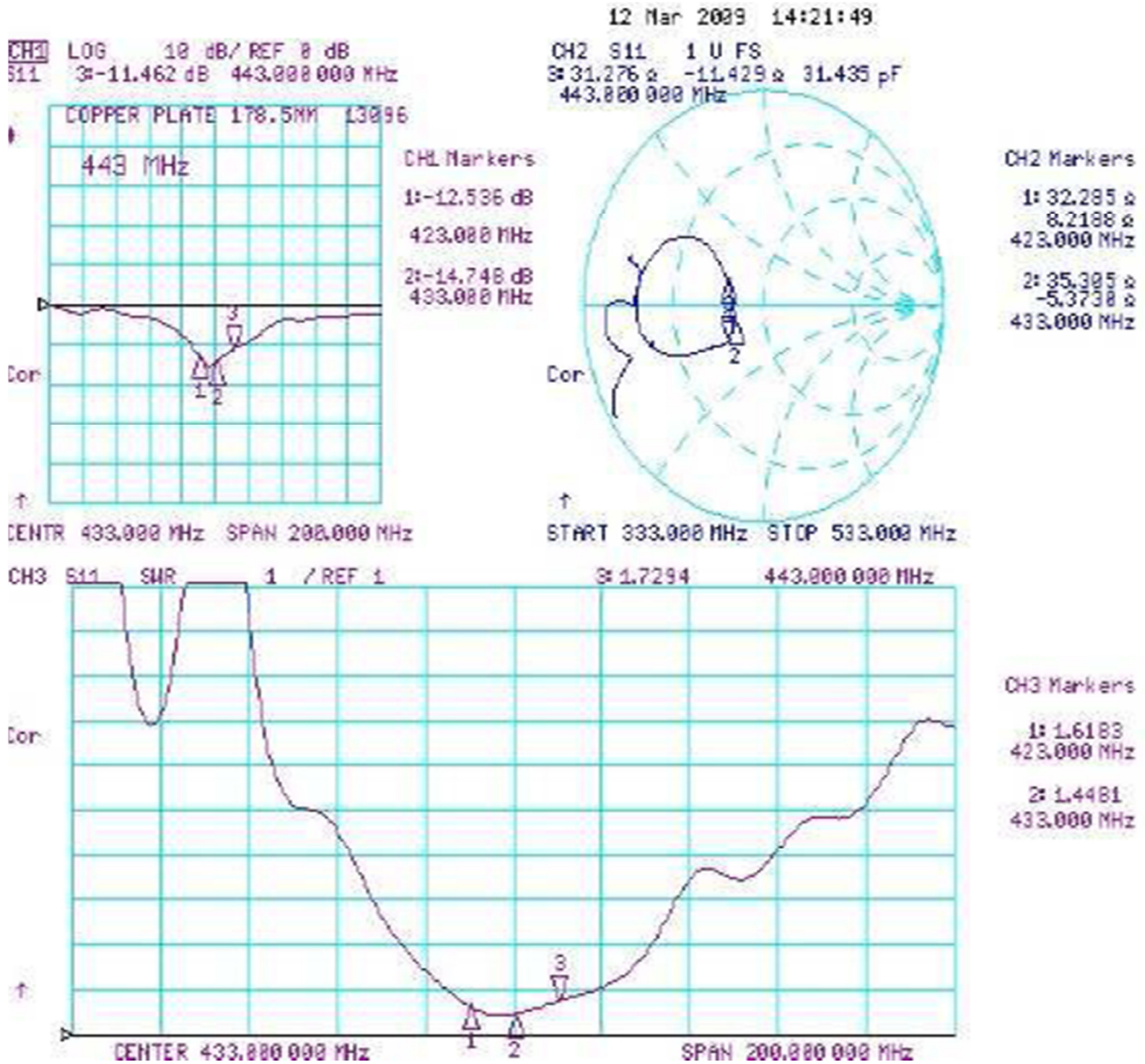

R F Solutions Ltd.,  
William Alexander House, William Way,  
Burgess Hill, W. Sussex. RH15 9AG. England.  
Email : [sales@rfsolutions.co.uk](mailto:sales@rfsolutions.co.uk) <http://www.rfsolutions.co.uk>  
Tel: +44 (0)1444 227 900 Fax: +44 (0)1444 227 898