

Rittal – The System.

Faster – better – everywhere.

Spacer for roof plate – DK 7967.000

Date : Apr 26, 2021

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



Spacer for roof plate – DK 7967.000

created: 26.04.2021 build on www.rittal.com/uk-en

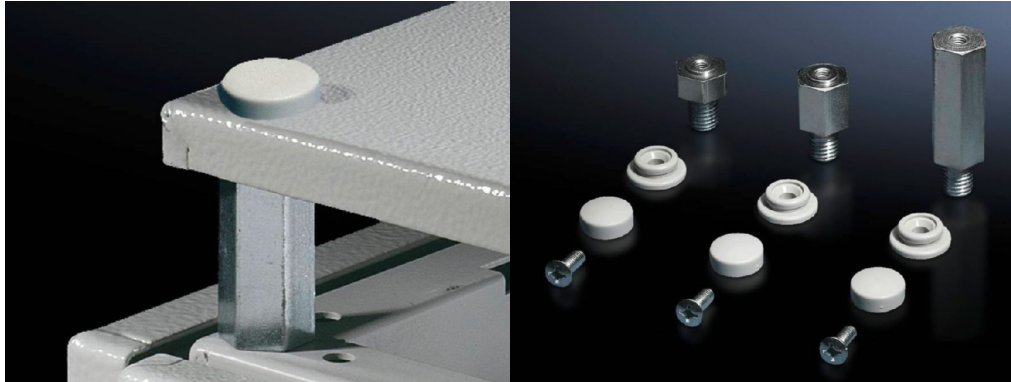

Product description

Description: To raise the roof for ventilation purposes, in three different heights.

Material: Hexagon steel section

Surface finish: Zinc-plated

Assembly instruction: Not suitable for crane transportation

Supply includes: Assembly parts

Product description

To fit: Enclosure type: VX
Enclosure type: TS

Dimensions: Height: 50 mm

Thread: Type: M12

Packs of: 4 pc(s).

Weight/pack: 0.54 kg

Copper weight (kg per piece): 0

EAN: 4028177186934

Customs tariff number:	73181900
ETIM 7.0:	EC002625
ETIM 6.0:	EC002625
eCl@ss 8.0/8.1:	27189234
eCl@ss 6.0/6.1:	27182405
Product description:	DK Spacer, L: 50 mm, For TS roof plate
Approvals	
Certificates:	NA