

Actuator

704.642.0

Distribution by
Rs-online



<https://rs-online.eao.com/p/704.642.0>

Your product:



704.642.0 Actuator

FRONT

Front dimension: Ø 29 mm

Front form: Round

MOUNTING

Design: Raised

Mounting type: Panel mounting

ELECTRICAL CHARACTERISTICS

Standards: The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1

MECHANICAL CHARACTERISTIC

Weight: 0.006 kg

AMBIENT CONDITION

IP Protection: IP65 front side

Operating temperature: – 40 °C ... + 55 °C

Storage temperature: – 40 °C ... + 85 °C


CERTIFICATE

REACH: REACH compliant


RoHS: RoHS compliant

OTHER

Short Description:	Actuator, Ø 29 mm, Round
Housing colour:	Grey
Housing material:	Plastic
Product attributes:	Without built-in series resistor
Wiring diagrams:	

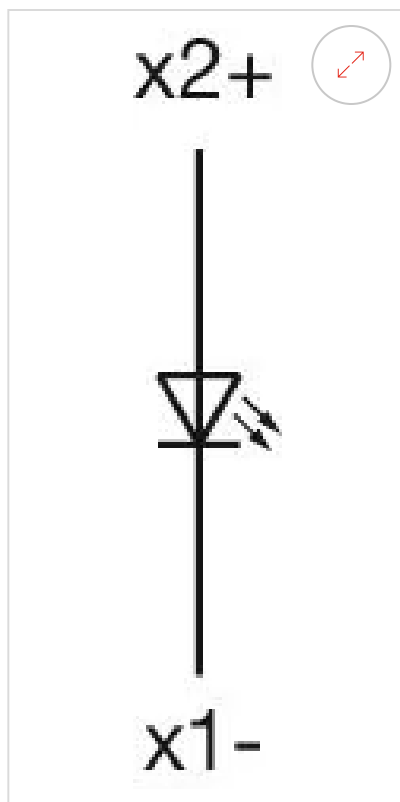

Mounting cut-outs:

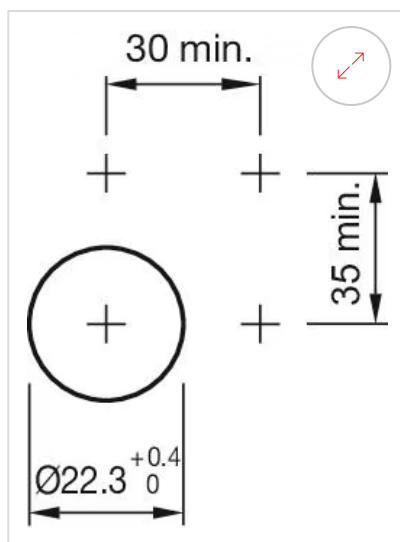

Dimension drawings:

