


LINOLITE LED / LED STRIP-LIGHT

■ S19 Tube opale - non dimmable / Opal glass not dimmable

CODE	REF.	V	W		Lm		°K	ENERGY CLASS	N°
▶ Ø 38 mm X h 310 mm - 230 V - IRC > 80									
180600	LE 8510 WW	230	7	41	550	360	2700	A+	1

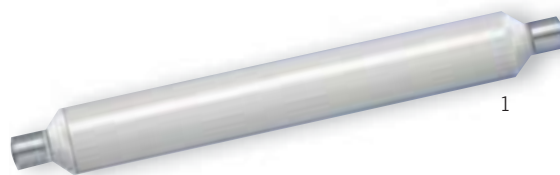


■ S14S Tube opale - non dimmable / S14S LED opal glass not dimmable

CODE	REF.	V	W		Lm		°K	ENERGY CLASS	N°
▶ Ø 30 mm X 300 mm - 230 VAC - IRC > 80									
180667	LE 8514 WW	230	5	35	400	270	2700	A+	2
▶ Ø 30 mm X 500 mm - 230 V - IRC > 80									
180618	LE 8512 WW	230	8	60	650	270	2700	A	2



■ S15 - Tube opale - non dimmable / S15 LED opal glass not dimmable

CODE	REF.	V	W		Lm		°K	ENERGY CLASS	N°
▶ Ø 26 mm X 221 mm - 230 VAC - IRC > 80									
180670	LE 8515 WW	230	4	30	300	270	2700	A+	4

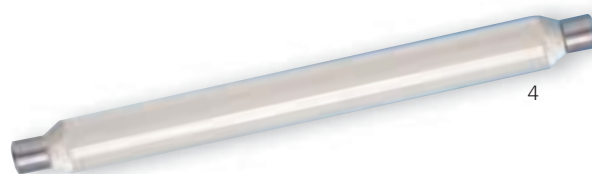

■ S14D - Tube opale - non dimmable / S14D LED opal glass not dimmable

CODE	REF.	V	W		Lm		°K	ENERGY CLASS	N°
▶ Ø 30 mm X 300 mm-230 VAC -IRC > 80									
180668	LE 8516 WW	230	5	35	400	270	2700	A+	5
▶ Ø 30 mm X 500 mm - 230 VAC - IRC > 80									
180669	LE 8518 WW	230	8	60	650	270	2700	A+	5

