




ENGLISH

Datasheet

RS PRO SLIM CAT6 RJ45 FRONT MOUNTING FT CONNECTOR

Stock No: 2188318, 2188321

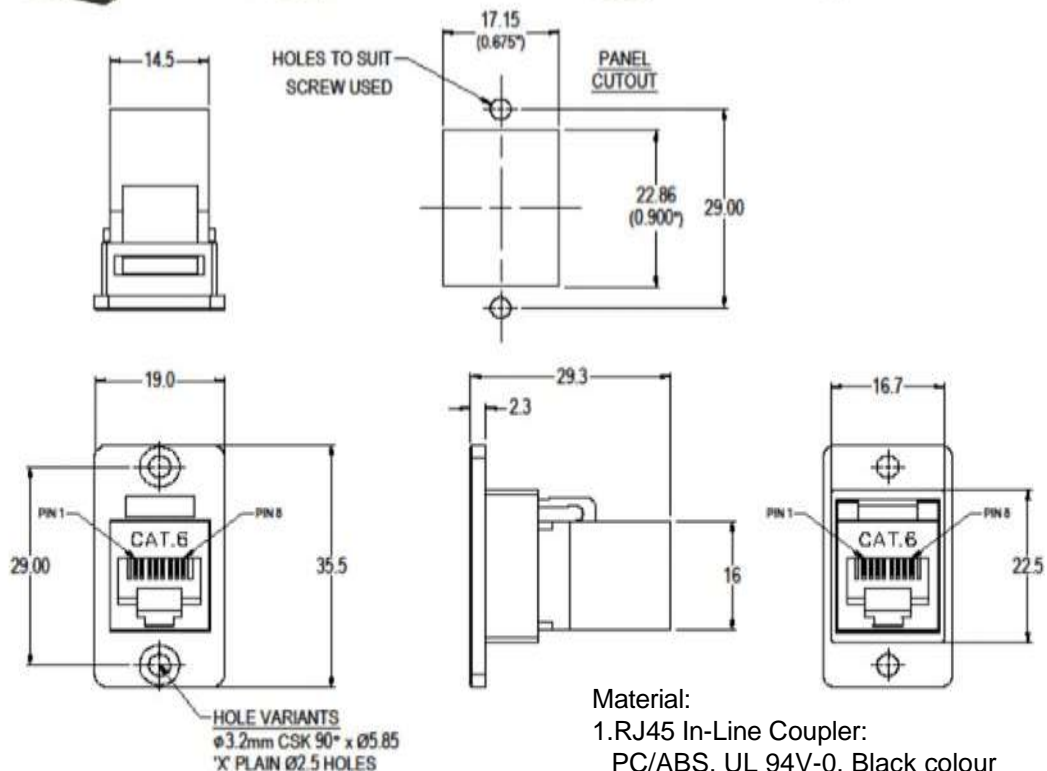

Performance:

- T568A & T568B wiring.
- Meet ISO/IEC 11801 and EN50173
- Meet ANSI/TIA/EIA 568B.2
- Operating temperature: Min -10°C Max +60°C

rspro.com

Material:

- RJ45 In-Line Coupler:
PC/ABS, UL 94V-0, Black colour
- RJ45 In-Line Coupler Contact:
Phosphor Bronze, 3-50 micro inches gold plating over nickel plate.
- PCB: FR4, UL 94V-0
- Frame: Polyamide UL94 V-2

Features & Benefits:

- Fits standard rectangular cutout.
- Various hole mounting options
- No soldering or punch termination. Use standard cable for each connector style.
- Low rear profile

General:

Please note: Functionality is affected by cable quality, length and cable wiring configuration.

Other models available:

Part No.

2188318 **FM SLIM FT Cat6 RJ45 Black plastic frame, CSK holes**

2188321 **FM SLIM FT Cat6 RJ45 Black plastic frame, Ø2.5 PLAIN holes**

