



**ENGLISH**

Datasheet

**Stock No. 170-4262**

## **RS PRO LED Floodlight**





### **SPECIFICATIONS**

|                    |                    |
|--------------------|--------------------|
| Watt               | 20W                |
| Work Voltage       | AC85-265V          |
| Configuration Size | L180.9*W141*H116mm |
| Light Color        | cool white         |

14/09/2017


|                         |                     |
|-------------------------|---------------------|
| Color Temperature       | 6000-6500K          |
| LED Angle               | 120°                |
| Led Luminous Efficiency | $\geq 80-90$ lm/w   |
| Led Flux                | $\geq 1600-1800$ lm |
| Lamp's Efficiency (%)   | $> 90\%$            |
| Life Span               | 50000H              |
| Protection Degree       | IP65                |
| Certificate             | CE & ROHS           |

**Dimensions:**

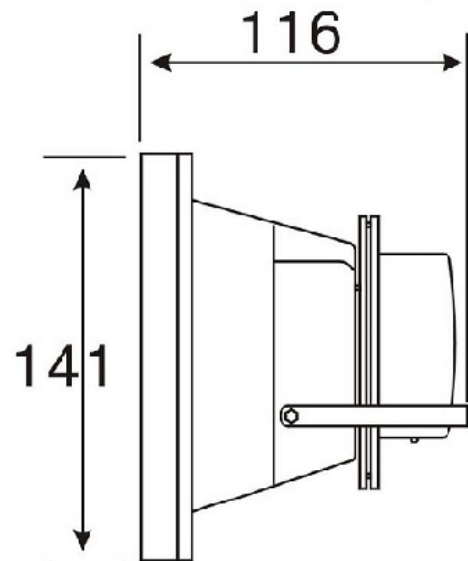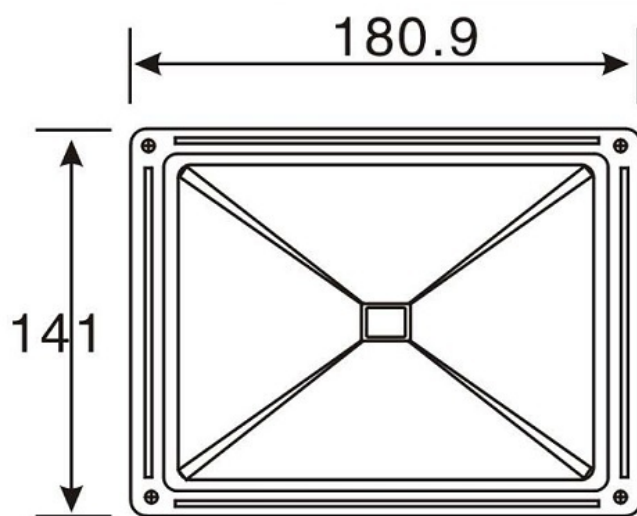


## How to assemble:


### Step 1:

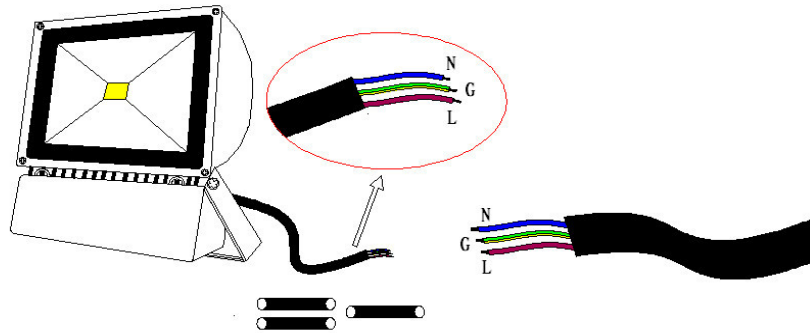

### Step 2:

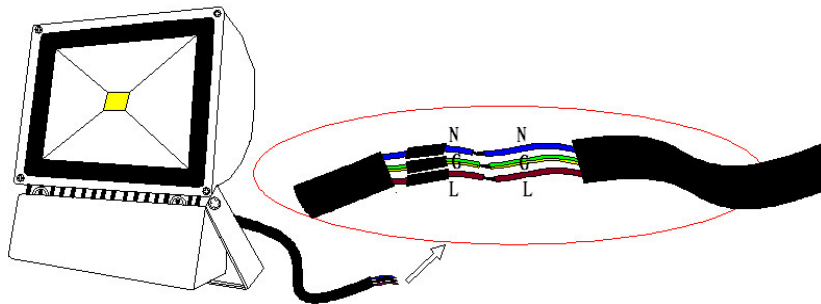

### Step 3:

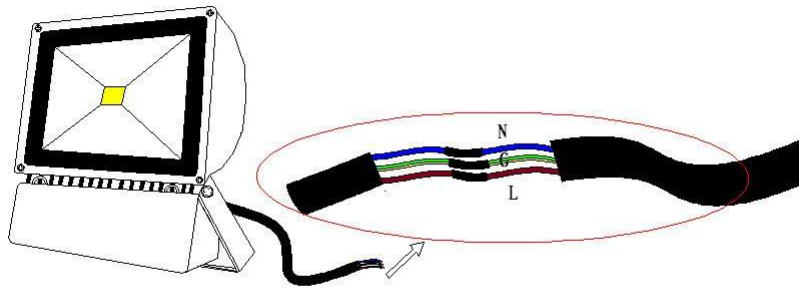

**Feature:**

**Energy-saving Lighting.**

**Applications:**

**Floodlights are for bars, clubs, hotels, plazas, commercial buildings facade, stages, squares, museums, art galleries, historical buildings, billboards, theatres, parks, gardens, etc.**