


# DumoCut® 655.1

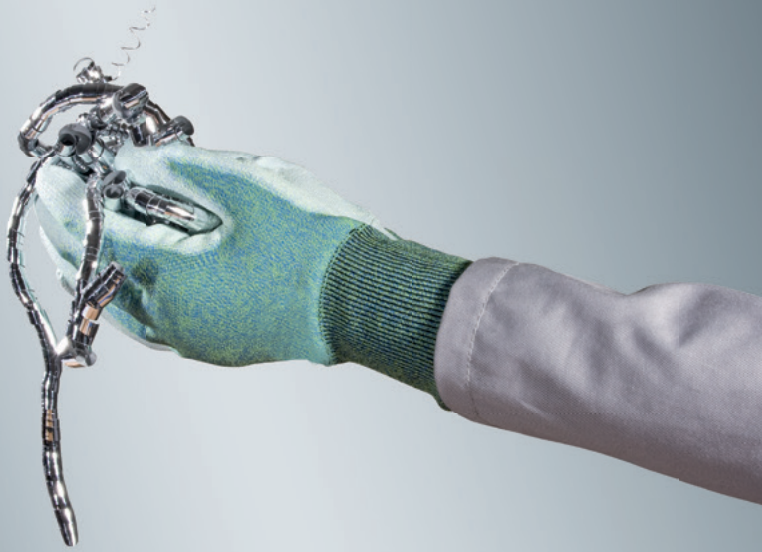

## APPLICATION

- › metal and plastics processing
- › handling of sharp-edged materials
- › mechanical engineering
- › automotive and supply industry
- › storage and commission works

## QUALITIES AND ADVANTAGES

- › high flexibility
- › very good sensitivity
- › very good grip
- › high mechanical resistance



|                      |                                                                                                                                |
|----------------------|--------------------------------------------------------------------------------------------------------------------------------|
| Article no.<br>Name  | 655.1<br>DumoCut® 655.1                                                                                                        |
| Material             | glass fibre,<br>polyamide,<br>polyurethane                                                                                     |
| Description          | seamless liner,<br>knit wrist,<br>palm coated                                                                                  |
| Length (mm)          | 230 - 290                                                                                                                      |
| Total thickness (mm) | 1,05 ± 0,10                                                                                                                    |
| Colour               | green-blue/white                                                                                                               |
| Size                 | 6, 7, 8, 9, 10, 11                                                                                                             |
| Classification       | category II<br>EN 388:2016<br><br>4 X 4 1 B |



## FEATURES

- › moisture-repellent PU palm coating
- › palm coated
- › not washable

[www.kcl.de](http://www.kcl.de)  
[sales@kcl.de](mailto:sales@kcl.de)



by Honeywell

## KCL GmbH

Industriepark Rhoen  
Am Kreuzacker 9  
36124 Eichenzell  
Germany  
Phone +49 6659 87-300  
Fax +49 6659 87-318

**Honeywell**