


FEATURES

- **UV Resistant:** Ensures longevity and performance in outdoor conditions.
- **High Tensile Strength:** Supports up to 34 kg, providing robust cable management.
- **Nylon Material:** Offers durability and flexibility for various applications.
- **UL 94 V-2 Fire Behaviour:** Provides a level of flame retardancy for added safety.
- **203 mm Length:** Suitable for a wide range of bundling needs.
- **4.6 mm Width:** Balances strength and flexibility for secure fastening.

RS PRO UV Protected Cable Tie, 203 mm Nylon

RS Stock No: 656-116

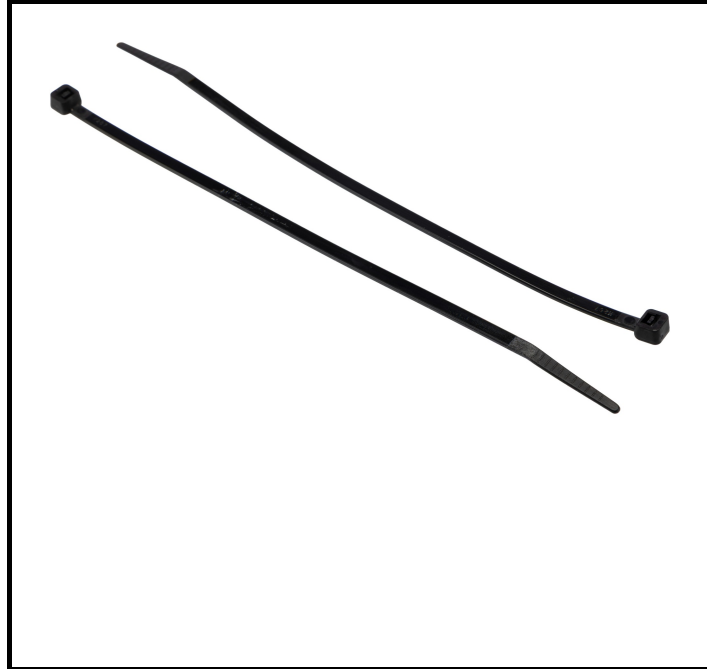

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

The RS PRO UV Protected Cable Tie is designed for secure and reliable bundling of cables and wires in various environments. Made from durable nylon, this cable tie offers excellent resistance to UV radiation, making it ideal for outdoor applications. With a maximum bundle diameter of 48 mm, it provides a versatile solution for organising cables efficiently.

General Specifications

Colour	Black
Product Type	Cable Tie
Sub Type	UV Protected Cable Tie
Tensile Strength	34 kg

Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	Yes

Mechanical Specifications

Length	203 mm
Material	Nylon
Maximum Bundle Diameter	48 mm
Width	4.6 mm

Operation Environment Specifications

Maximum Operating Temperature	85 °C
-------------------------------	-------

Approvals

Standards/Approvals	ABS 15-TA1338482-PDA, cULus E97527, RoHS, UL94V-2
---------------------	---

