

Datasheet


EES30A Series

30W External Power Supply



Features:

- 30W external power supply
- Protections: Short circuit/ Overload/ Over voltage
- Input voltage range: 100 to 240VAC
- Fully enclosed plastic case
- Efficiency: Up to 80%
- Dimensions (LxWxHmm) 107x 43x 31
- 1.2m DC cable with 2.1mm connector
- 2 year warranty
- AC inlet C14 socket
- Meets CEC level IV or V
- ErP step 2 compliant
- Designed to meet TUV, CB, CCC
- CE Approved

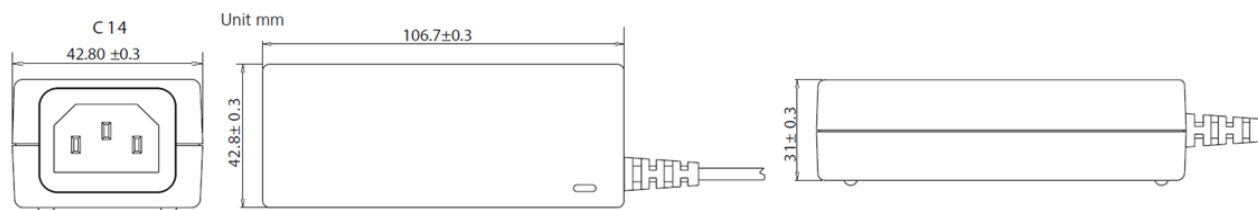

Part Number	Voltage	Rated Current	Efficiency	Line Regulation	Load Regulation	Operating temp	MTBF
	12	2.5A	80%	±1.0%	±5%	-10°C-+50°C	500khrs
	15	2.0A	80%	±1.0%	±5%	-10°C-+50°C	500khrs
	18	1.67A	80%	±1.0%	±5%	-10°C-+50°C	500khrs
	24	1.25A	80%	±1.0%	±5%	-10°C-+50°C	500khrs
	30	1.0A	80%	±1.0%	±5%	-10°C-+50°C	500khrs
	36	0.83A	80%	±1.0%	±5%	-10°C-+50°C	500khrs
	48	0.63A	80%	±1.0%	±5%	-10°C-+50°C	500khrs