



Linear Scale AT715-150

Item number: 539-802N

Images



Description

This linear scale is based on electro magnetic induction principle thus offering you high enviroment protection IP level, in the mean time reference point is not necessary after each power on.


Only compatible with KA series display units.

Features

|                   |                                                                         |
|-------------------|-------------------------------------------------------------------------|
| Measuring method: | Electromagnetic induction system                                        |
| Accuracy:         | 100 to 500 mm ±5 µm;<br>600 to 1800 mm ±7 µm;<br>2000 to 3000 mm ±10 µm |
| Max. drive speed: | 50 m/min                                                                |
| Signal period:    | 20 µm                                                                   |

|                   |                                        |
|-------------------|----------------------------------------|
| Resolution:       | 0,001 / 0,005 (switchable via Counter) |
| Cable length:     | 3.5 m                                  |
| Effective Length: | 150 mm                                 |
| Mass:             | 0.75 kg                                |

Dimensions

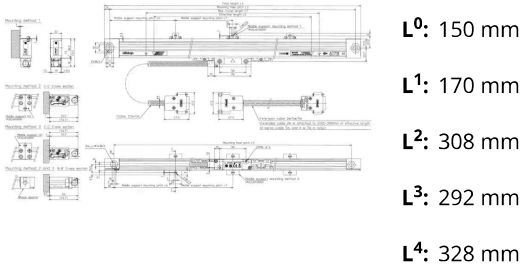

Accessories

Optional accessories:



Linear Scale Counter KA-212

Art No. 174-183D  
Suggested retail price: 650.00 €\*  
Suggested retail price: 650.00 €\*  
Suggested retail price: 650.00 €\*

Extension Cable 2m

for AT715  
Art No. 09AAB674A  
Suggested retail price: 211.00 €\*  
Suggested retail price: 211.00 €\*





### Extension Cable 5m

for AT715

Art No. 09AAB674B

Suggested retail price: **297.00 €\***



### Extension Cable 7m

for AT715

Art No. 09AAB674C

Suggested retail price: **361.00 €\***



### Linear Scale Counter KA-213

Art No. 174-185D

Suggested retail price: **782.00 €\***