

V23101D 103B201


✕ OBSOLETE

Axicom | Axicom W11 Relay V23101

TE Internal #: 2-1393779-7

TE Internal Description: V23101D 103B201

[View on TE.com >](#)

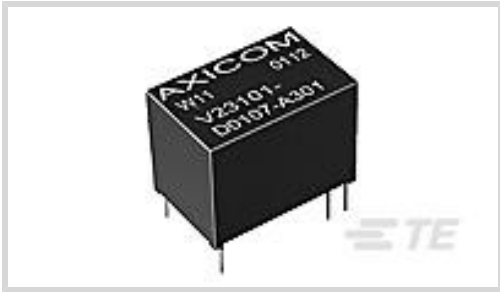

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2022 (223) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Also in the Series | [Axicom W11 Relay V23101](#)



DC Relays(25)

Electromechanical Relays(25)

PCB Relays(25)

Customers Also Bought

TE Part #1-1462038-2
IM02NS=IM RELAY 140mW 4.5V

TE Part #737439-1
250 FASTON REC 22-18 AWG BR

TE Part #1-2331929-0
SCL 1.0 HDR DRV T USP 020 SMT G3 TBK

TE Part #2-2176346-5
CRGCQ 1210 10K 5%

TE Part #3-1534904-4
CONNECTOR HSG 94 POS.

TE Part #CAT-T4827-T273
TIMER, RECEPTACLE AND TAB

TE Part #1-2267440-0
SCL 1.0 RCPT DR VT 020 SMT G3 TBK

TE Part #NB16572001
RW-175-3/32-X-STK

TE Part #2362764-2
MATENET,CABLE ASSY,1 GBPS UTP

Documents

- CAD Files
 - Customer View Model
 - ENG_CVM_CVM_2-1393779-7_B1.3d_igs.zip
 - English
 - Customer View Model
 - ENG_CVM_CVM_2-1393779-7_B1.3d_stp.zip
 - English
 - Customer View Model
 - ENG_CVM_CVM_2-1393779-7_B1.2d_dxf.zip



English

3D PDF

3D

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Product Specification

English

Definitions General Purpose Relays

English