




LED/Multiled	LED	Optimum voltage (V)	2Vdc	Intensity	1300mcd@20mA
Mounting Size	14mm	Rectifier			
Mounting Finish	Chrome Bezel	AC current			
Protection	IP67	DC current	20mA (max)		
Mount Holder	Flush	Voltage Tolerance (%)	10%		
Chip Qty	1	Optimum temperature (°C)	-40°C...+85°C		
Indicator colour	Yellow	Storage temperature (°C)			
Wavelength (nm)	589	Contact Tab x 2	22AWG wire		

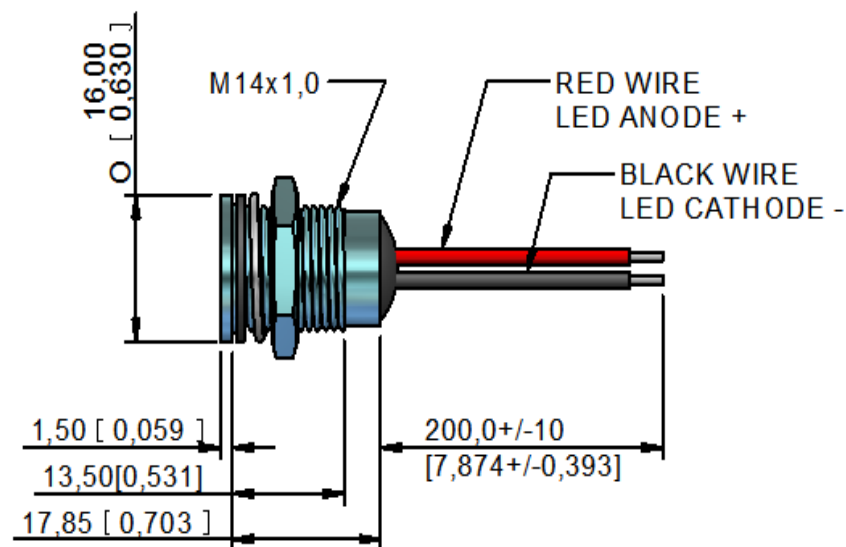

Dimension in mm (typical), not to scale.

We reserve the right to make changes without further notice to this product to improve reliability, function or design.