

compact Pin Busbar, 10mm<sup>2</sup> connection: 3p/N AFDD 5SM6 +  
compact device 1-pole touch protected 1000mm cuttable



Versie	
productmerksnaam	SETRON
Algemene technische gegevens	
aantal fasen	3
Elektriciteit	
continustroom / nominale waarde	63 A
Hoofd-circuit	
bedrijfsspanning / nominale waarde / maximaal	230 V
Geschiktheid	
<b>geschiktheid voor samenwerking</b>	
• apparaten met hulpschakelaar	Geen
• apparaten met nulgeleider	Ja
Product Details	
producteigenschap / elektrisch geïsoleerd	Ja
Aantal	
aantal apparaten / geschikt voor aanbouw	30

## Aansluitingen

uitvoering van de elektrische aansluiting	Stift
---	-------

## Mechanical Design

verdelingsmaat	2 mm
hoogte	13 mm
lengte	1 042,4 mm
nettogewicht	580 g

## Certificaten

### Declaration of Conformity



EG-Konf.

## Verdere informatie

### Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

### Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/nl/nl/Catalog/product?mlfb=5ST3775-0>

### Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/nl/ps/5ST3775-0>

### Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=5ST3775-0](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5ST3775-0)

### CAx-Online-Generator

<http://www.siemens.com/cax>

### Tender specifications

<http://www.siemens.com/specifications>

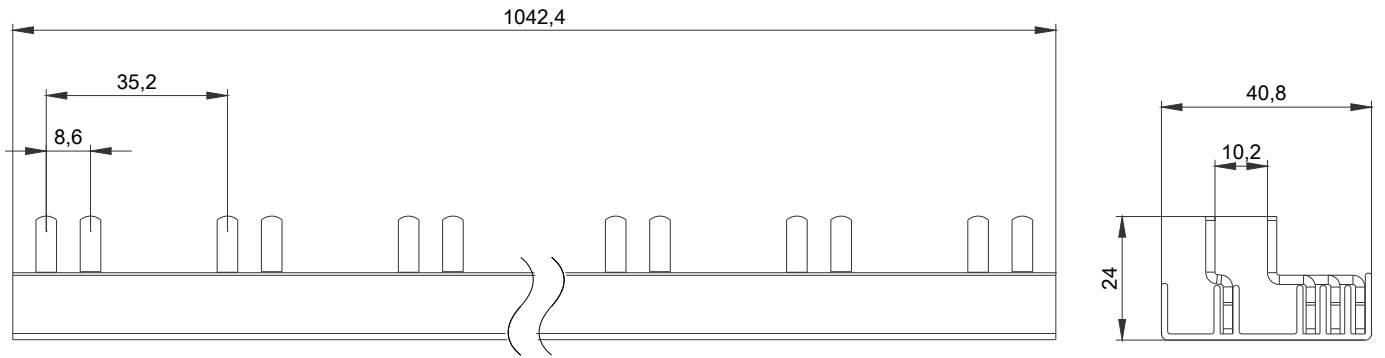

5ST3775-0

