




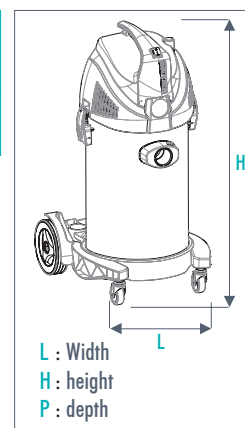
> JET 30 i
Wet and dry vacuum cleaner-Stainless steel tank

Characteristics :

- European-made
- Semi-automatic unclogging device of the filter, through a push button
- Water resistant high 99.9 % efficiency PET cartridge filter
- Metal accessories and stainless steel tube
- Hemp-reinforced base to respect environment resources
- Storage space into the base for accessories
- Large base with 2 wheels + 2 castors for an optimised balance
- No-crushing reinforced hose
- Dual-turbine sucking up

- Motor designed for continuous intensive uses. By-pass type cooling down (air is sucked up through a th turbine fitted over the motor, only for cooling down)
- No-static electricity plate connected to reath
- Power cable made from neoprene HO7 RNF - length 7 m
- Standard supplied accessories:
 - Bent tubes 2 x 500 mm Ø 40 mm
 - Hose Ø 40 mm, length 2,5 m
 - Dry nozzle: 400 mm
 - Liquid nozzle: 400 mm
 - Round brush
 - Flat nozzle
 - Accessories collector
 - Grade M cartridge filter

	Tank	Tank volume (L)	Tank (L) capacity	Power (W)		Vacuum (Kpa)	Flot rate (l/min)	Noise level (dBA)	Ø Accessory (mm)	 (kg)	Size L x H x p (mm)	
JET 30 i	Inox	38	35	1200	230 V mono	23,52	3600	74	40	12,8	435 x 800 x 530	20402041



..... JET 30 i

✓ Use tip :

These devices are not designed to collect poisonous dusts, (flour, asbestos, lead, flammable materials...).

