


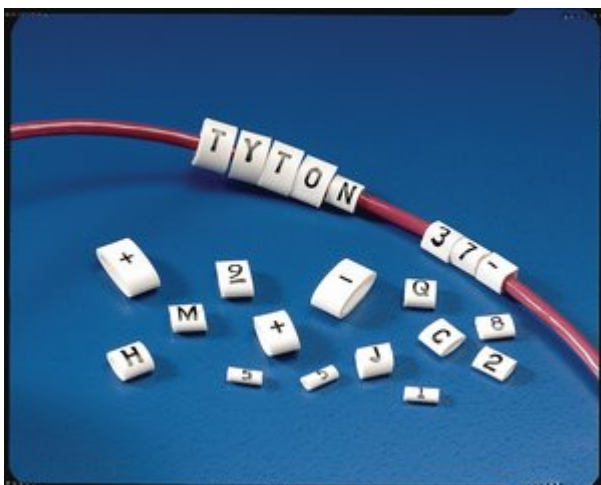
## HODC50-PVC-BN : HODC50

Article number: 533-02035

 Add to watchlist



 Images (1)



### Features

- Gives the ability to lock markers together so ensuring that the text legend stays in place
- Directly mountable onto the cable as pre-termination marker
- Shape gives a snug fit onto the cable, ensuring the markers do not easily slip down or around the wire

contact 

## Certifications & Approvals



### Application

Ovalgrip HODC markers are supplied on reels of 1000 and are supplied in colour code and pink. HODC are supplied in bags of 500 and are supplied colour code and yellow.

Sizes 50 and 85 can be used with Arrowtags for identifying larger cable bundles.

AT1 Arrowtags will fit 7 size 50 markers.

AT2 Arrowtags will fit 8 size 85 markers.

AT3 Arrowtags will fit 14 size 85 markers.

### Base Data

Colour	Brown (BN)
Colour of Print	Black (BK)
Fixation Method	Suspend
For Size	AT1
Marking Text	1
Pack Cont.	1000 pcs.
Package Content in	reel
PART DESCRIPTION	HODC50-PVC-BN
With label space	No

### Product Dimensions

Length (L)	4.0 mm
Outside $\varnothing$ max (OD max.)	3.60 mm
Outside $\varnothing$ min. (OD min.)	1.7 mm
Print Method	Hotfoil printing

### Material and Specifications

Flammability	self-extinguishing
Material	Flexible Polyvinyl Chloride, cadmium free (PVC)
Operating Temperature - °C	-65 °C to +105 °C, intermittent +135 °C
Specifications	
Specifications	BS-2782-540B, IEC 304, IEC 757

### Logistics and Packaging

Contact



ETIM 7.0 Key

EC001530

---

© HellermannTyton 2022

**Contact** 