




ENGLISH

Datasheet

Stock No: 522-430

RS Pro 3 Core YY Control Cable Unscreened Polyvinyl Chloride PVC Sheath

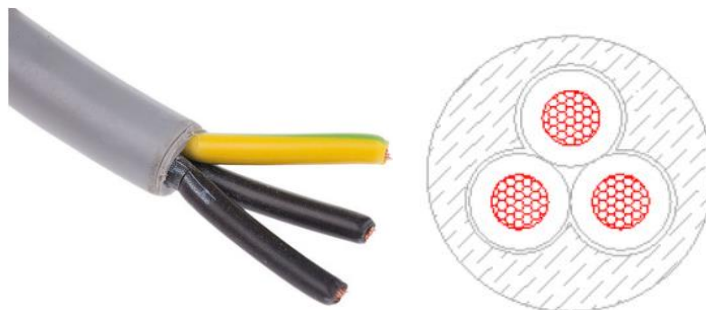

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Electrical Characteristics:

Max. Conductor DC Resistance at 20°C (Ω/Km) :
<28.1

Min. Insulation DC Resistance at 20°C (MΩ*KM) :
>500

Current Rating : 6 A

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): 0.20±0.008 x 24

Insulation: PVC

Insulation Dia. (mm): 2.34±0.1 x 3C

Filler: Chalk

Jacket: PVC

Outer Dia. (mm): 6.15±0.25

Colour:

The colour of the insulation: Black x 2 ,
Yellow/Green

The jacket colour: Grey (RAL-7001)

Marking(3times/m):

RS 522430 YY/NR 3 Core x 0.75mm²