

Features

- Max. Display 1999
- Manual Range
- Diode Test
- Continuity Test
- Auto Power Off
- Temperature
- Capacitance
- Power: Battery 6F22(9V)X1
- Size: 91x189x31.5mm
- Weight: ~310g (including battery)

RS PRO Digital Multimeters

RS Stock No.: 296671



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.


Product Description

296671 is a completely portable manual range meter and designed for use by electricians, technicians, servicemen and hobbyists who require an instrument that is accurate, reliable, and always ready for use.

General Specifications

Function	Value
DC Voltage	200m/2/20/200V \pm 0.5%, 1000V \pm 0.8%
AC Voltage	200mV \pm 1.2%, 2/20/200V \pm 0.8%, 700V \pm 1.2%
DC Current	2mA/20mA \pm 0.8%, 200mA/2A \pm 1.5%, 10A \pm 2%
AC Current	20mA \pm 1%, 200mA \pm 1.8%, 10A \pm 3%
Resistance	200/2K/20K/200K/2M Ω \pm 0.8%, 20M Ω \pm 1.8%, 200M Ω \pm 5.0%
Temperature	-20°C ~ 0°C \pm 5%, 0°C ~ 400°C \pm 1.0%, 400°C ~ 1000°C \pm 2.0%

Panel and Constructure

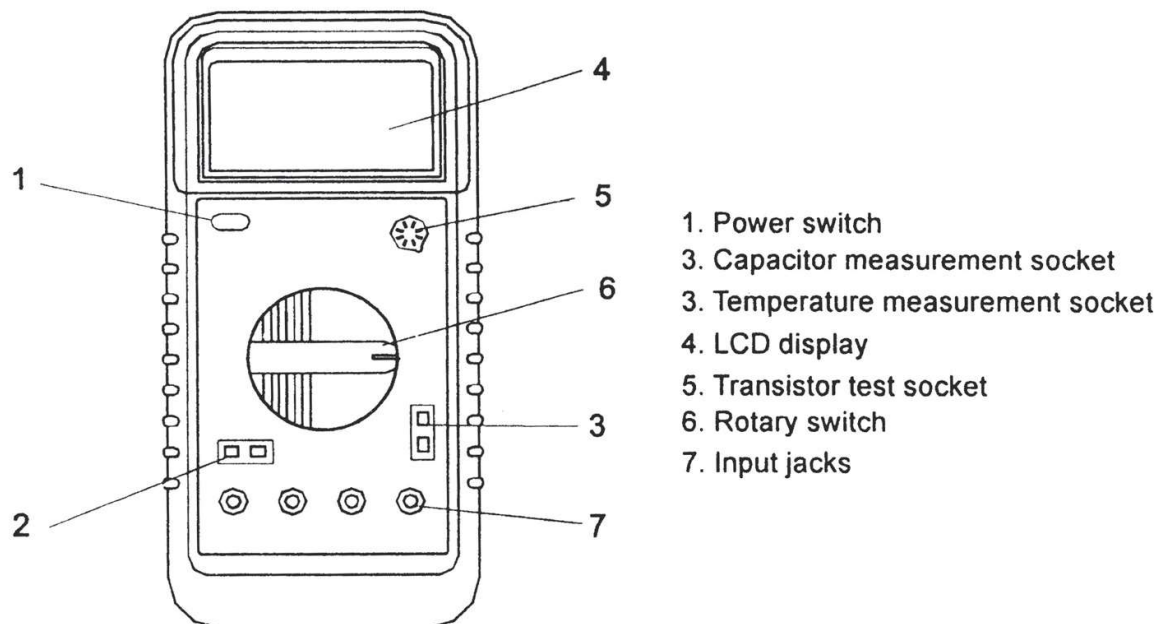

Contents



L200 x W100 x D50mm
L7.9"x W3.9"x D2.0"
464g/ 1.02lb



Battery 9V
6F22x 1




Accessories

Test Leads
K-type Thermocouple
Battery



User
Manual

Packaging Information


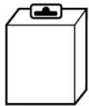


Color Box
L 170 X W 65 X H 240mm


Main Applications




Domestic

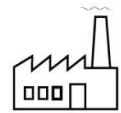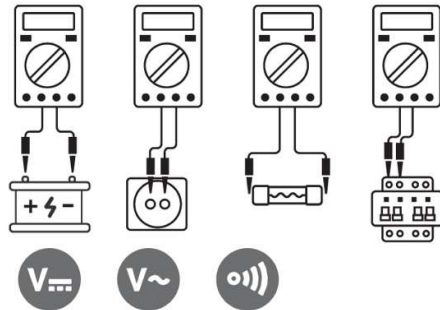

Industrial

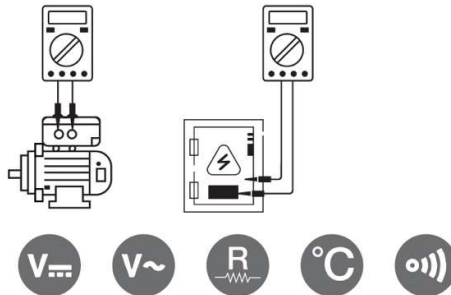

Electronics

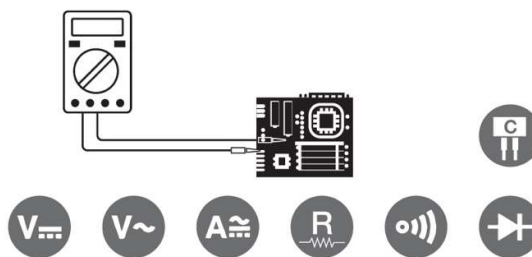

Order Details

Stock No.	Brand	Product Name	Multimeter Type	Functions Measured	Digit Resolution
296671	RS Pro	Digital Multimeters	Handheld	1000V DC 700V AC, 10A AC/DC, Ω , CAP, Hz, $^{\circ}\text{C}$	-