


GEBERIT

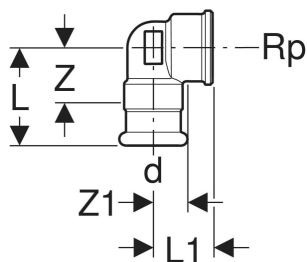

Example image

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water $\leq 120\text{ }^{\circ}\text{C}$
- For service water and process water
- For compressed air (oil purity class 0–3)

- For negative pressure
- For inert gases (e.g. nitrogen)
- For technical building systems, industry and shipbuilding

- Pressing indicator
- Leaky if unpressed

- Seal ring made of CIIR, black
- Pressing socket with transparent protection plug

Product material	Gunmetal / lead-free gunmetal
------------------	-------------------------------

Page 1

<i>Art. no.</i>	<i>DN</i>	<i>d_ø mm</i>	<i>R_p "</i>	<i>Product material</i>	<i>arc °</i>	<i>L cm</i>	<i>L1 cm</i>	<i>Z cm</i>	<i>Z1 cm</i>
63863	15 / 20	18	3/4	Gunmetal	90	3.8	3.1	1.8	1.6
63864	20 / 15	22	1/2	Gunmetal	90	3.8	3.2	1.7	1.9
63855	20	22	3/4	Gunmetal	90	4.5	2.7	2.4	1.2
63856	25	28	1	Lead-free gunmetal	90	5.1	3.3	2.8	1.6
63857	32	35	1 1/4	Gunmetal	90	5.5	4.5	2.9	2.6
63865	40	42	1 1/2	Lead-free gunmetal	90	6.7	5.2	3.7	3.3
63866	50	54	2	Gunmetal	90	7.4	6	3.9	3.7