


Floor infostand with aluminum snap frame A3

Article number	479923	Sales unit quantity	1 Piece
Colour	Silver	Sales unit EAN	4005546735559
Packaging unit	1 piece	Packing weight (gross)	2196 G
Base EAN	4005546735559	Country of origin	CN

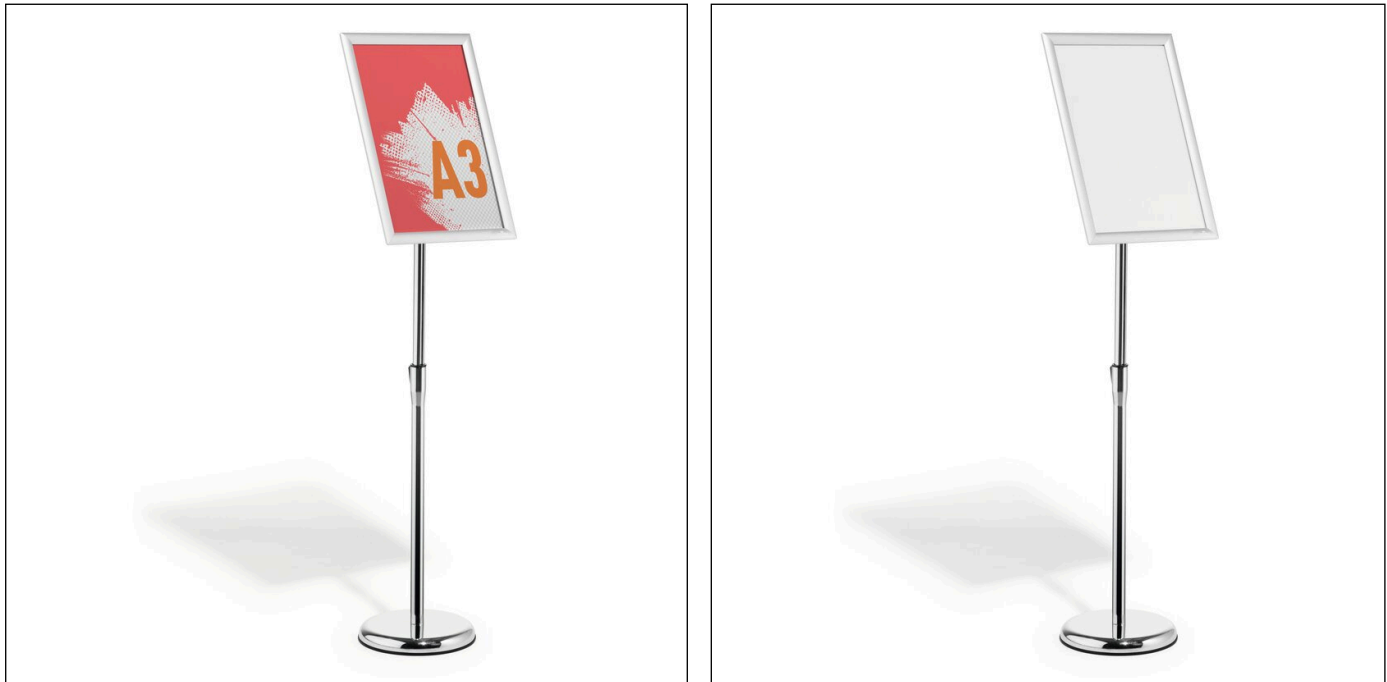

Logos and awards



Product description

- Quickly assembled information stand with robust DIN A3 aluminium folding frame, silver anodised
- High stability can be ensured by optionally filling the base (diameter: 250 mm) with sand. Additional purchase item DURABLE Sand: Product code 333516. Max. weight approx. 1.1 kg
- Round base with enclosed rubber ring prevents scratches on the floor
- Height adjustable with telescopic rod. Can be adjusted in steps from 860 mm to a maximum height of 1,290 mm in portrait format
- Folding frame can be easily rotated from portrait to landscape format
- Reading angle adjustable by ball-and-socket joint
- Low-reflection, UV-resistant protective cover
- Impact-resistant polystyrene back panel
- Mitred corners
- Ideal for restaurants, retail, museums, exhibitions, trade fairs, reception and waiting areas, conference rooms etc.

Floor infostand with aluminum snap frame A3

Product features

Outer width (mm)	250
Outer height (mm)	1290
Outer Ø (mm)	250
Filling quantity / Filling quantity for	1 Sheet
Format / Format for	A3
Orientation Format	Portrait / landscape
Brand	DURABLE
Inner display panel width (mm)	278
Inner display panel height (mm)	402
Set includes display panels	Yes
Height adjustable	Yes
Rotate / Swivel amounts	360°
Adjustable reading angle	5° - 90°
Opening for documents	4-sided
Tabs with blank labels included	No
Non-slip / Stable	Non-slip / stable
Includes assembly instructions	Yes
Antibacterial	No
Product features relating to documents	Anti-glare
Base / mount type	Floor stand