

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130299-0200](#)
Status: **Active**
Overview: [Brad® Micro-Change® \(M12\) Connectors](#)
Description: [Brad® Micro-Change® \(M12\) Harsh-Duty Receptacle, 4 Pole, D-Code, Vertical](#)

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-130299-001 \(PDF\)](#)


General
Product Family Industrial Receptacles
Series [130299](#)
IP Rating IP67
Overview [Brad® Micro-Change® \(M12\) Connectors](#)
Product Name Micro-Change® (M12)
Type PCB Mount
UPC 78172513053

Physical
Coupling Type Internal Thread
Gender Female
Keyway D-coded
Length N/A
Material - Component Nickel-plated Zinc Die-Cast
Mounting Thread Size M12 x 1.0
Orientation Straight
Panel Mount Back, Front
Poles 4
Temperature Range - Operating -40°C to +85°C
Wire Size AWG N/A
Wire/Cable Type N/A

Electrical
Current - Maximum per Contact 4A
Voltage - Maximum 250V AC/DC

Material Info

Reference - Drawing Numbers
Product Specification PS-130299-001
Sales Drawing SD-130299-006

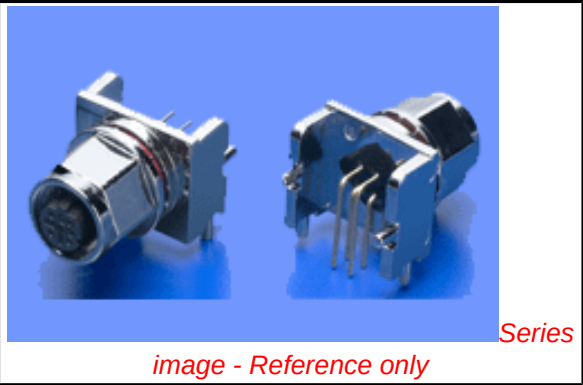

EU RoHS
RoHS Compliant by Exemption
REACH SVHC
Contains SVHC: Yes
Dibutyl phthalate
Low-Halogen Status
Not Low-Halogen

China RoHS

Need more information on product environmental compliance?
Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)
Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[130299Series](#)

Mates With
Male D-Code Cable Assembly