

# 19" CABINETS

## CamRack-QX




Flat packed-Assembled in **3 minutes!**

19" Wall mounted cabinets, designed for cabling, telecommunications, IT and industrial and home installations

- Delivered flat packed for ease of access to all installations. Also reduces associated logistic costs and offers greater protection during transit
- Fast and efficient 3 minute assembly *without tools*
- 2x 19" mounting profiles. Variable depth, in 20mm increments
- Fast fixings 1/4 turn locks
- Quick release door. Tempered, smokey safety glass
- Easily removable side panels with 2x 1/4 turn locks
- Easily drilled plastic blanking covers for cable entry
- Template for wall mounting, included
- Maximum recommended load capacity: 45kg

Finishes: Epoxy paint, Ral 7016

Delivery: Flat packed with carrying handle

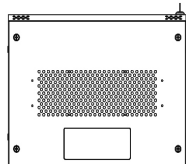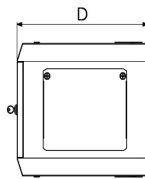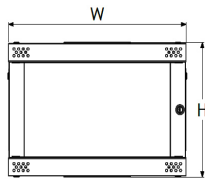

RED	U	WIDTH	DEPTH	HEIGHT
CQX064211	6U	580mm	421mm	384mm
CQX094211	9U	580mm	421mm	517mm
CQX125211	12U	580mm	521mm	651mm
CQX155211	15U	580mm	521mm	784mm
* CQX186211	18U	580mm	621mm	917mm



Red Corner

\* Special orders only

UNIVERSAL ENCLOSURES

HAND HELD CASES

HEAVY DUTY ENCLOSURES

DIN RAIL BOXES

INTERFACE SUPPORTS

CONTROL STATIONS

DIECAST & METAL BOXES

DESKTOP & INSTRUMENT CASES

POTTING BOXES

19" ENCLOSURES

19" SUBRACKS

CUSTOM SIZED ENCLOSURES

CUSTOM SERVICES