



+FLEX 160

IP20 Flexible LED Tape

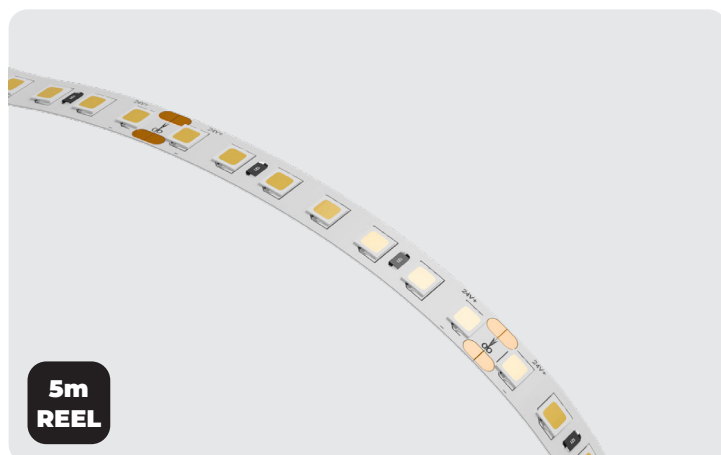


Product Features

 - Available in four different colour temperatures
- Industrial grade adhesive backing tape
- Bespoke design and cutting service available
- Operating temperature -20°C ~ +45°C
- Humidity 40% - 70% RH
- High efficacy
- 3 years warranty



Specifications

Stock Code	0148-603 	1090-320 	1321-974 	1088-948 
Part Code	B7-2-160-20	C0-2-160-20	D0-2-160-20	F0-2-160-20
Voltage	24VDC	24VDC	24VDC	24VDC
Power Consumption	8.2W/m	8.2W/m	8.2W/m	8.2W/m
Lumen Output	1200lm/m	1300lm/m	1330lm/m	1330lm/m
Efficacy	146lm/W	159lm/W	162lm/W	162lm/W
Colour Temperature	2700K	3000K	4000K	6000K
LED/metre	160	160	160	160
LED Pitch	6.25mm	6.25mm	6.25mm	6.25mm
Cut Points	50mm	50mm	50mm	50mm
CRI (Ra)	>80	>80	>80	>80
IP Rating	IP20	IP20	IP20	IP20
Dimensions	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm

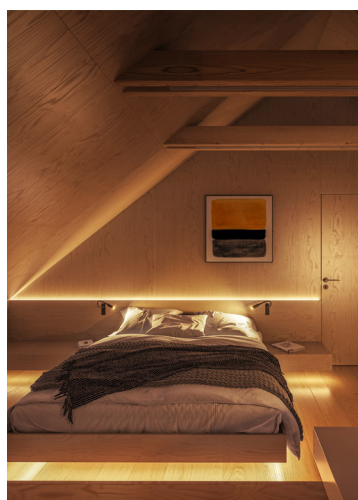

2700K



3000K



4000K




6000K




+FLEX 160

IP65 Flexible LED Tape

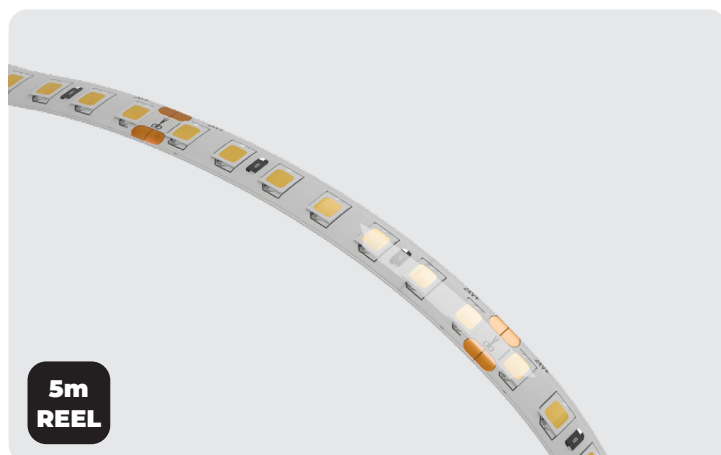

Product Features

 - Available in three different colour temperatures
- Industrial grade adhesive backing tape
- Bespoke design and cutting service available
- Operating temperature -20°C ~ +45°C
- Humidity 40% - 70% RH
- High efficacy
- 3 years warranty



Specifications

Stock Code	0729-260 	0647-357 	1367-921 
Part Code	C0-2-160-65	D0-2-160-65	F0-2-160-65
Voltage	24VDC	24VDC	24VDC
Power Consumption	8.2W/m	8.2W/m	8.2W/m
Lumen Output	1184lm/m	1184lm/m	1210lm/m
Efficacy	145lm/W	145lm/W	147lm/W
Colour Temperature	3000K	4000K	6000K
LED/metre	160	160	160
LED Pitch	6.25mm	6.25mm	6.25mm
Cut Points	50mm	50mm	50mm
CRI (Ra)	>80	>80	>80
IP Rating	IP65	IP65	IP65
Dimensions	5000 x 8 x 2.2mm	5000 x 8 x 2.2mm	5000 x 8 x 2.2mm



3000K



4000K



6000K




+FLEX 160

IP20 & IP65 Flexible LED Tape



Compatibility*

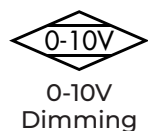

Suggested Drivers

Non-Dimmable

Up to 1m

Power supplied from ONE end
PCV2420

Up to 3m

Power supplied from ONE end
PCV2436-REV-A

Up to 5m

Power supplied from ONE end
PCV2450-REV-A

Up to 10m

Power supplied from MIDDLE
PCV24101-REV-A

Mains Dimming

Up to 1m

Power supplied from ONE end
UVC2425TD-REV-A

Up to 3m

Power supplied from ONE end
UVC2425TD-REV-A

Up to 5m


Power supplied from ONE end
UVC2450TD-REV-A

Up to 10m


Power supplied from MIDDLE
UVC24100TD-REV-A

Mechanical Diagram

IP20

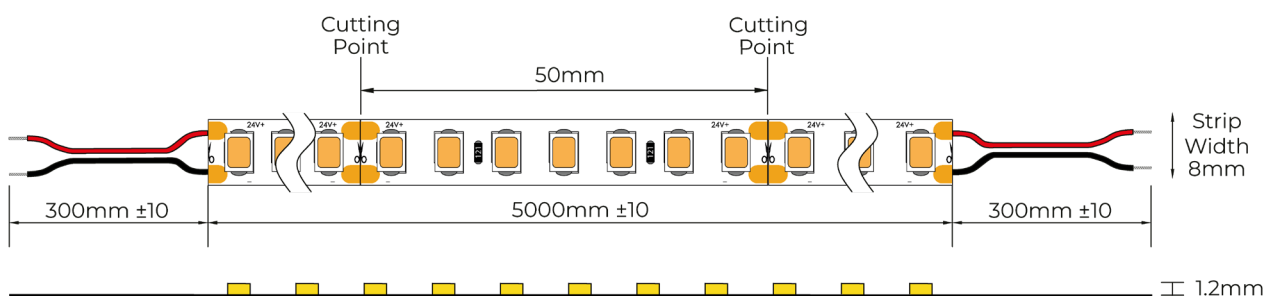

IP65

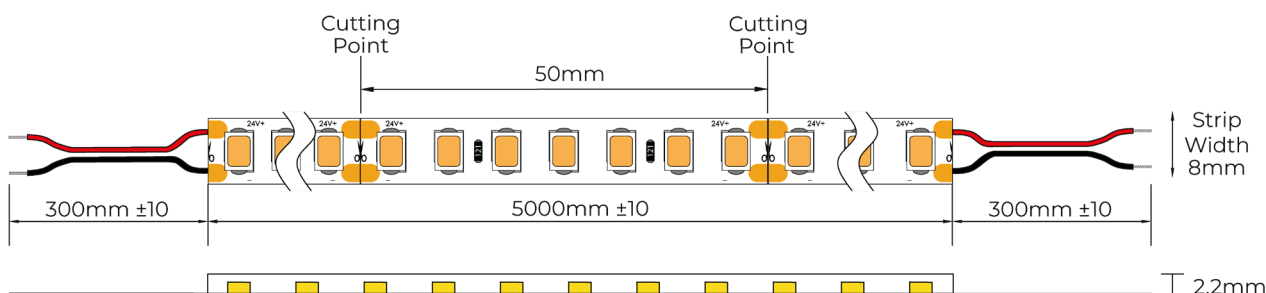

* Product compatibility with other brands is shown for informational purposes only. All third-party company names and logos are trademarks of their respective owners and do not constitute an endorsement or partnership with our company.