


## clevis foot LN-80

Part number: 5151

**FESTO**

For swivel mounting of cylinders DNC, DNGU, DNGUT, DNG, DNU, AEVU, ADVU, ADVUP, ADVUP.

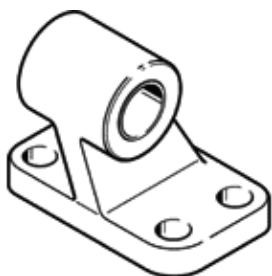

### Data sheet

Feature	Value
Size	80
Based on the standard	ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-40 ... 150 °C
Product weight	877 g
Materials note	Free of copper and PTFE Conforms to RoHS
Material mounting	Nodular graphite cast iron